

0312 KSS MARKER TIE




UNIT : mm



Item No.	Length		W	Max.Bundle Dia.	Min LoopTensile Strength		Marking pad A X B	Packing
	mm	inch			lbs	kgs		
MCV-100	100	4"	2.5	23	18	8	8 X 25	100 pcs
MCV-100L	130	5 1/8"	2.5	22	18	8	28X 20	
MCV-110	110	4 3/8"	2.5	20	18	8	8 X 25	
MCV-200	200	8"	4.6	50	50	22	28 X 13	
MCV-200S	200	8"	2.5	50	18	8	15 X 30	
NEW MCV-200SS	200	8"	2.5	50	18	8	8 X 25	
MCV-270	270	11"	4.6	75	50	22	28 X 13	
NEW MCV-300	300	11 7/8"	4.8	82	50	22	54.5 X 13	100 pcs
NEW MCV-370	370	14 9/16"	4.8	105	50	22	54.5 X 13	

- Material: UL approved Nylon 66, 94V-2
- Tie and identify bundles of cable in one operation.Flat areas may be imprinted or written on with a Marking Pen.

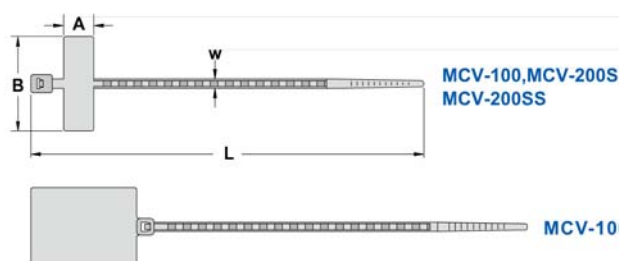

0313 KSS SECURITY MARKER TIE



UNIT : mm


PATENT

Item No.	Length		W	Max.Bundle Dia.	Marking pad A X B	Min LoopTensile Strength		Packing
	mm	inch				lbs	kgs	
SCT-110	111	4 3/8"	2.6	20	8 X 27.6	11	5	100 pcs
SCT-250	248.5	10"	3.5	50	36 X 19	22	10	
SCT-400	400	15 3/4"	4.8	102	36.5 X 19	55	25	

- Material: UL approved Nylon 66, 94V-2
- Feature: for the purpose of identification for security service logistics, transportation and courier.
The size of marker plate could be made or carved LOGO upon customer's request.

