


## Connect Lock Duct ■UL Approved Component

**Ro** Product in compliance with RoHS Directive

### ● Cross Section

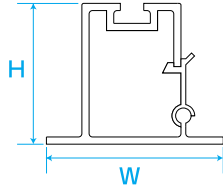

### Material

- Rigid vinyl chloride (Self-extinguishing material rated 94V-0)

### Color

- Gray

### Quantity

- 10 pieces

(Unit: mm)

Type	W	H	Length
KDCR-A	72	58	1,200

 
\*With side and bottom holes

Electric-Materials

### Exclusive nut for KDCR

**Ro**

Product in compliance with RoHS Directive



Type	Quantity
KDN-4	200


### Surface Treatment

- Trivalent chromate treatment

## Separator ■UL Approved Resin Used

**Ro** Product in compliance with RoHS Directive

### ● Cross Section

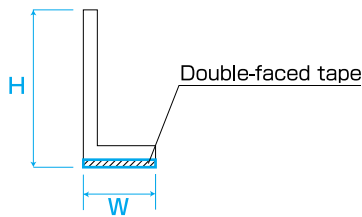

### Material

- Rigid vinyl chloride (Self-extinguishing material rated 94V-0)

### Color

- Gray

### Quantity

- 10 pieces

### ■Separator without side hole    ■H type separator with side hole

Type	W	H	Length	Type	W	H	Length
KDS-60	12	55	1,000	KDS-60H	12	55	1,000
KDS-80	15	75		KDS-80H	15	75	
KDS-100	15	95		KDS-100H	15	95	

(Unit: mm)

\*Standard product: Includes mounting hole and double-faced tape.

\*Also available without mounting hole or tape upon request.