


• ブッシング 〈B〉

材質：SCS13A

単位：mm

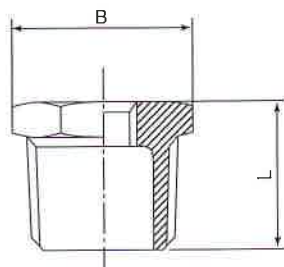


呼び径		長さ L	二面幅 *B
(A)	(B)		
8×6	1/4×1/8	18	15
10×6	3/8×1/8	19	18
10×8	3/8×1/4	19	18
15×6	1/2×1/8	22	24
15×8	1/2×1/4	22	24
15×10	1/2×3/8	22	24
20×8	3/4×1/4	25	29
20×10	3/4×3/8	25	29
20×15	3/4×1/2	25	29
25×8	1×1/4	28	36
25×10	1×3/8	28	36
25×15	1×1/2	28	36
25×20	1×3/4	28	36
32×10	1 1/4×3/8	31	44
32×15	1 1/4×1/2	31	44
32×20	1 1/4×3/4	31	44
32×25	1 1/4×1	31	44
40×15	1 1/2×1/2	33	51
40×20	1 1/2×3/4	33	51
40×25	1 1/2×1	33	51
40×32	1 1/2×1 1/4	33	51
50×20	2×3/4	37	63
50×25	2×1	37	63
50×32	2×1 1/4	37	63
50×40	2×1 1/2	37	63

*B：大径側 ～1/2…六角、3/4～2…八角

• キャップ 〈C〉

材質：SCS13A

単位：mm

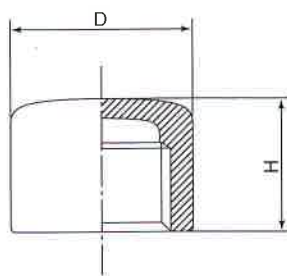


呼び径		外径 D	高さ H
(A)	(B)		
6	1/8	15	15
8	1/4	19	17
10	3/8	22	18
15	1/2	28	21
20	3/4	32	25
25	1	40	26
32	1 1/4	50	33
40	1 1/2	56	33
50	2	70	38

• プラグ 〈P〉

材質：SUS304(1/8B～3/4B)
材質：SCS13A(1B～2B)

単位：mm

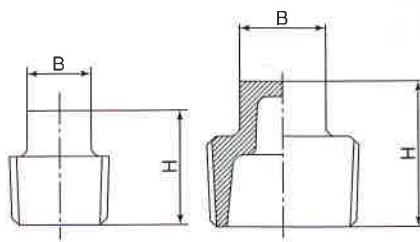

呼び径		高さ H	B
(A)	(B)		
6	1/8	15	7
8	1/4	19	9
10	3/8	21	12
15	1/2	26	14
20	3/4	29	17
25	1	32	19
32	1 1/4	35	22
40	1 1/2	37	25
50	2	41	31