


ストレートソケット〈S〉

材質：SUS304

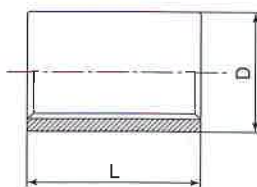


単位：mm

呼び径		外径 D	長さ L
(A)	(B)		
6	1/8	13.8	20
8	1/4	17	25
10	3/8	21	26
15	1/2	25	33
20	3/4	31	36
25	1	38	43
32	1 1/4	47	48
40	1 1/2	53	48
50	2	66	56
65	2 1/2	82	65
80	3	95	70
100	4	121	84

ハーフストレートソケット〈HS〉

材質：SUS304

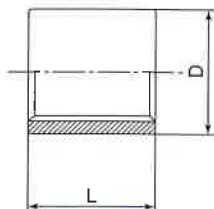


単位：mm

呼び径		外径 D	長さ L
(A)	(B)		
6	1/8	13.8	12
8	1/4	17	15
10	3/8	21	16
15	1/2	25	20
20	3/4	31	21
25	1	38	25
32	1 1/4	47	28
40	1 1/2	53	28
50	2	66	34
65	2 1/2	82	39
80	3	95	42
100	4	121	50

テーパソケット〈PTS〉

材質：SUS304

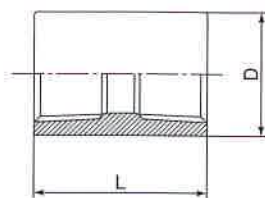

単位：mm

呼び径		外径 D	長さ L
(A)	(B)		
6	1/8	15	23
8	1/4	19	29
10	3/8	22	30
15	1/2	27	38
20	3/4	33	40
25	1	40	45
32	1 1/4	49	51
40	1 1/2	55.5	54
50	2	68	64
65	2 1/2	83	73
80	3	97	81
100	4	125	93

ハーフテーパソケット〈HPTS〉

材質：SUS304



単位：mm

呼び径		外径 D	長さ L	l / min
(A)	(B)			
8	1/4	19	18	9.4
10	3/8	22	18	9.7
15	1/2	27	21	12.7
20	3/4	33	21	14.1
25	1	40	25	16.2
32	1 1/4	49	27	18.5
40	1 1/2	55.5	27	18.5
50	2	68	32	22.8