


• ストレート厚ロケット (JISソケット) <SJ>

材質: SUS304

単位: mm

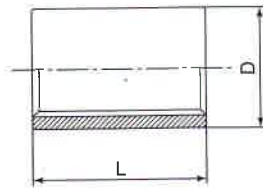


呼び径		外径 D	長さ L
(A)	(B)		
8	1/4	19	27
10	3/8	23	28
15	1/2	28	37
20	3/4	34.5	39
25	1	41.5	46
32	1 1/4	51	51
40	1 1/2	58	51
50	2	70	60

• 異径ソケット <SR>

材質: SCS13A


単位: mm

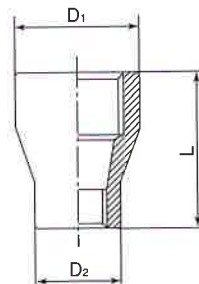

呼び径		外径		長さ L
(A)	(B)	D ₁	D ₂	
8×6	1/4×1/8	19	15	25
10×6	3/8×1/8	23	15	28
10×8	3/8×1/4	23	19	28
15×8	1/2×1/4	27	19	34
15×10	1/2×3/8	27	23	34
20×10	3/4×3/8	33	23	38
20×15	3/4×1/2	33	27	38
25×15	1×1/2	41	27	42
25×20	1×3/4	41	33	42
32×20	1 1/4×3/4	50	33	48
32×25	1 1/4×1	50	41	48
40×20	1 1/2×3/4	56	33	52
40×25	1 1/2×1	56	41	52
40×32	1 1/2×1 1/4	56	50	52
50×25	2×1	69	41	58
50×32	2×1 1/4	69	50	58
50×40	2×1 1/2	69	56	58

• 丸型サイホン <MO>

材質: SUS304
呼び径: 10A (3/8B)

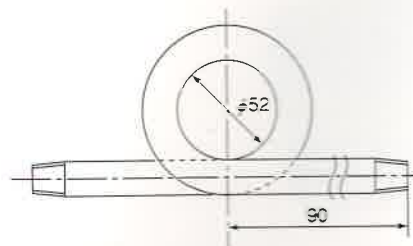

• U型サイホン <MU>

材質: SUS304
呼び径: 10A (3/8B)

