


JIS B2401-1 V番(真空フランジ用)

V

断面AAの拡大 (単位: mm)

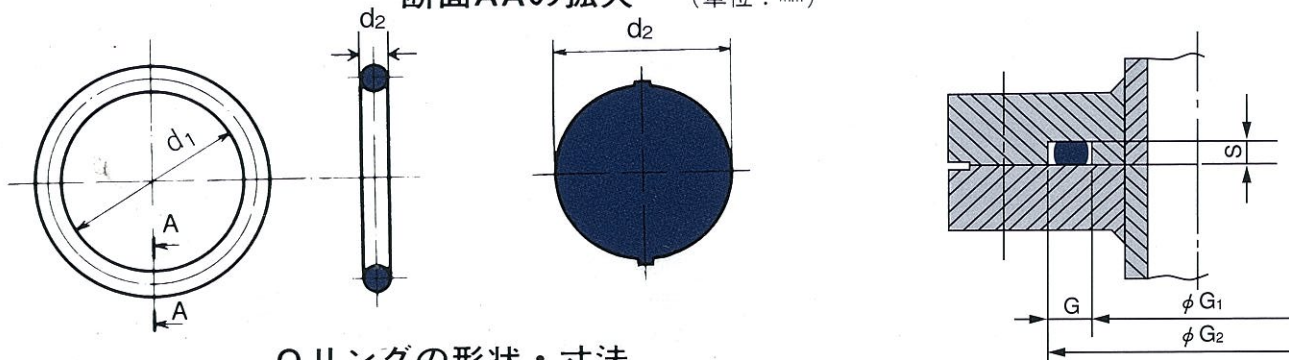

○リングの形状・寸法

※寸法公差につきましては、19ページ(5)と同様ですのでご参照して下さい。

部品番号	JIS 呼び番号	○リング寸法					フランジみぞ部の寸法 (JIS B2290)					
		太さ d_2	内径			呼び径	G_1	G_2	G	S		
			d_1	材質群①	材質群②						材質群③	
30010	※V10	4.0±0.1	9.5	±0.20	±0.24	±0.30		10				
30011	※V11		10.5	±0.20	±0.24	±0.30		11				
30012	※V12		11.5	±0.20	±0.24	±0.30		12				
30014	※V14		13.5	±0.20	±0.24	±0.30		14				
30015	V15		14.5	±0.20	±0.24	±0.30		15		25		
30016	※V16		15.5	±0.24	±0.29	±0.36		16				
30018	※V18		17.5	±0.24	±0.29	±0.36		18				
30020	※V20		19.5	±0.24	±0.29	±0.36		20				
30021	※V21		20.5	±0.24	±0.29	±0.36		21				
30022	※V22		21.5	±0.24	±0.29	±0.36		22				
30024	V24		23.5	±0.24	±0.29	±0.36	10	24		34		
30025	※V25		24.5	±0.33	±0.40	±0.50		25				
30026	※V26		25.5	±0.33	±0.40	±0.50		26				
30028	※V28		27.5	±0.33	±0.40	±0.50		28				
30030	※V30		29.5	±0.33	±0.40	±0.50		30				
30032	※V32		31.5	±0.33	±0.40	±0.50		32				
30034	V34		33.5	±0.33	±0.40	±0.50	20	34		44		
30035	※V35		34.5	±0.37	±0.45	±0.56		35				
30036	※V36		35.5	±0.37	±0.45	±0.56		36				
30038	※V38		37.5	±0.37	±0.45	±0.56		38	+1.0		5.0	3.0
30040	V40		39.5	±0.37	±0.45	±0.56	25	40	0	50		
30042	※V42		41.5	±0.49	±0.59	±0.74		42				
30044	※V44		43.5	±0.49	±0.59	±0.74		44				
30045	※V45		44.5	±0.49	±0.59	±0.74		45				
30046	※V46		45.5	±0.49	±0.59	±0.74		46				
30048	※V48		47.5	±0.49	±0.59	±0.74		48				
30050	※V50		49.5	±0.49	±0.59	±0.74		50				
30053	※V53		52.5	±0.49	±0.59	±0.74		53				
30055	V55		54.5	±0.49	±0.59	±0.74	40	55		65		
30056	※V56		55.5	±0.61	±0.74	±0.92		56				
30058	※V58		57.5	±0.61	±0.74	±0.92		58				
30060	※V60		59.5	±0.61	±0.74	±0.92		60				
30063	※V63		62.5	±0.61	±0.74	±0.92		63				
30065	※V65		64.5	±0.61	±0.74	±0.92		65				
30067	※V67		66.5	±0.61	±0.74	±0.92		67				
30070	V70		69.0	±0.61	±0.74	±0.92	50	70		80		
30075	※V75	74.0	±0.72	±0.87	±1.08		75					
30080	※V80	79.0	±0.72	±0.87	±1.08		80					
30085	V85	84.0	±0.72	±0.87	±1.08	65	85		95			
30090	※V90	89.0	±0.83	±1.00	±1.25		90					