


## ISO-KF フランジタイプ

### ■KFフランジ



◆寸法

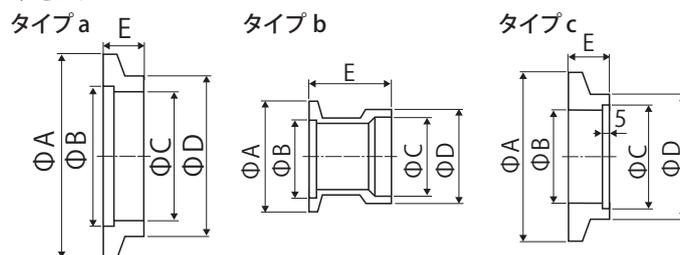

■材質…SUS304, SUS316L

■ Type a,b は突き合わせ外側溶接用 ■ Type c は差込内側溶接

※ SUS316L をご注文の際は、製品コード末尾に「-40」を付けてください。

※スケジュール表記については目安となります。


(単位: mm)

コード	フランジ	タイプ	ΦA	ΦB	接続パイプ	ΦC	ΦD	E
MCK-3010	KF 10	a	30	12.2	8A t=1.9 (10S)	10.0	13.8	10
MCK-3016	KF 16	a	30	17.2	Φ 20 t=2 (10S)	16.0	20.0	10
MCK-3016-SP	KF 16	b	30	17.2	15A t=1.85 (10S)	18.0	21.7	20
MCK-3025	KF 25	a	40	26.2	20A t=1.6 (5S)	24.0	27.2	20
MCK-3025-SP	KF 25	b	40	26.2	25A t=3 (10S)	28.0	34.0	30
MCK-3040	KF 40	a	55	41.2	32A t=1.85 (10S)	39.0	42.7	20
MCK-3040-SP	KF 40	b	55	41.2	40A t=3.55(40S)	41.5	48.6	30
MCK-3050	KF 50	a	75	52.2	50A t=2.75 (10S)	55.0	60.5	20
MCK-3063	KF 63	a	87	70.2	63A t=3.05(10S)	70.2	76.3	20
MCK-3080	KF 80	c	114	83.2	80A t=4.25(10S)	89.5	98.0	20
MCK-3080-SP	KF 80	a	114	83.1	80A t=3 (10S)	83.1	89.1	20
MCK-3100	KF100	c	134	102.2	100A t=3 (10S)	114.7	118.0	20
MCK-3100-SP	KF100	a	134	102.2	100A t=3 (10S)	108.3	114.3	20
MCK-3160	KF160	c	190	153.2	150A t=3.4 (10S)	165.6	170.0	20
MCK-3160-SP	KF160	a	190	153.2	150A t=3.4 (10S)	158.4	165.2	20
MCK-3200	KF200	c	252	213.2	200A t=4 (10S)	216.7	225.0	20
MCK-3200-SP	KF200	a	252	213.2	200A t=4 (10S)	208.3	216.3	20

### ■blankフランジ



◆寸法

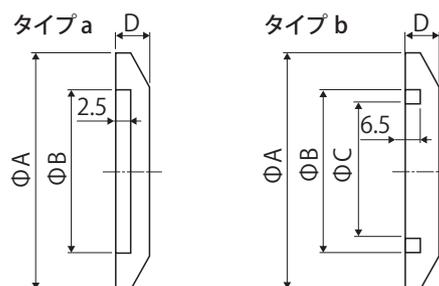

■材質…SUS304, SUS316L

※ SUS316L をご注文の際は、製品コード末尾に「-40」を付けてください。

(単位: mm)

コード	フランジ	タイプ	ΦA	ΦB	ΦC	D
MCK-4010	KF 10	a	30	12.2	-	6
MCK-4016	KF 16	a	30	17.2	-	6
MCK-4025	KF 25	a	40	26.2	-	6
MCK-4040	KF 40	a	55	41.2	-	6
MCK-4050	KF 50	a	75	52.2	-	6
MCK-4063	KF 63	a	87	70.2	-	6
MCK-4080	KF 80	b	114	83.0	73	11
MCK-4100	KF100	b	134	102.2	92	11
MCK-4160	KF160	b	190	153.2	143	11
MCK-4200	KF200	b	252	213.2	203	11