

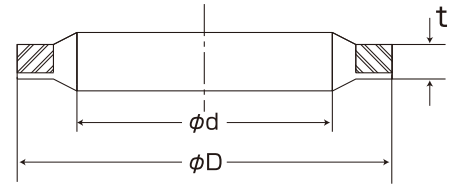
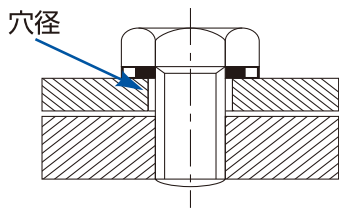


SW-A型 (頭付ボルト用 内径締め代なしタイプ)

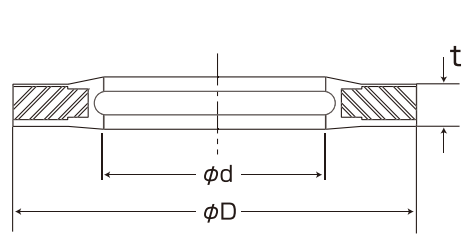

品番	適用穴径 最大 ϕ	呼び径 ϕ	内径 ϕd	外径 ϕD	厚み t	最大締め付けトルク N-cm (Kgf-cm)
SW 4X9 - A	4.5	4.0	4.3	9.0	1.0	588 (60)
SW 5X9 - A	5.5	5.0	5.5	9.0	1.0	784 (80)
SW 6X10 - A	6.5	6.0	6.5	10.0	1.2	1,225 (125)
SW 8X14 - A	8.5	8.0	9.0	14.0	1.6	2,156 (220)
SW 10X17 - A	11.0	10.0	11.0	17.0	1.6	3,724 (380)
SW 12X21 - A	14.0	12.0	13.5	21.0	2.0	6,174 (630)
SW 14X23 - A	16.0	14.0	15.5	23.0	2.0	9,310 (950)
SW 16X26 - A	18.0	16.0	17.5	26.0	2.0	12,740 (1,300)
SW 18X27 - A	20.0	18.0	18.5	27.0	2.0	19,600 (2,000)
SW 20X32 - A	23.0	20.0	22.0	32.0	2.3	28,420 (2,900)
SW 22X35 - A	25.0	22.0	24.0	35.0	2.3	39,200 (4,000)
SW 24X38 - A	26.0	24.0	26.0	38.0	2.3	49,000 (5,000)

SW-K型 (頭付ボルト用 内径締め代ありタイプ)

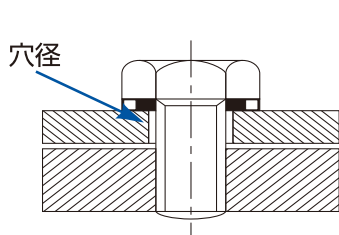

品番	適用穴径 最大 ϕ	呼び径 ϕ	内径 ϕd	外径 ϕD	厚み t	最大締め付けトルク N-cm (Kgf-cm)
SW 3X10 - K	3.5	3.0	2.8	10.3	1.3	392 (40)
SW 4X11 - K	4.5	4.0	3.8	11.3	1.3	784 (80)
SW 5X12 - K	5.5	5.0	4.8	12.3	1.3	1,225 (125)
SW 6X13 - K	6.5	6.0	5.8	13.3	1.3	2,156 (220)
SW 8X16 - K	8.5	8.0	7.8	16.3	1.3	2,156 (220)
SW 10X18 - K	10.5	10.0	9.8	18.3	1.3	3,724 (380)