

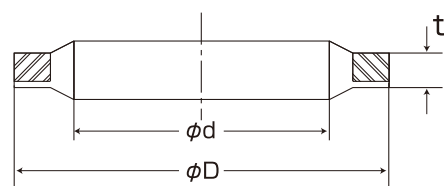
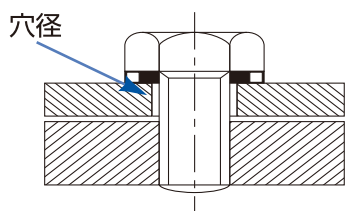


SWS-A型 (頭付ボルト用 内径締め代なしタイプ)

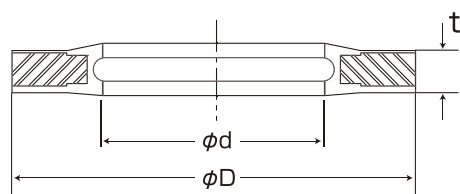

品番	適用穴径 最大φ	呼び径φ	内径φd	外径φD	厚みt	最大締め付けトルク N-cm (Kgf-cm)
SWS 3X6.4-A	3.4	3.0	3.1	6.4	1.0	245 (25)
SWS 4X9-A	4.5	4.0	4.3	9.0	1.0	588 (60)
SWS 5X9-A	5.5	5.0	5.5	9.0	1.0	784 (80)
SWS 6X10-A	6.5	6.0	6.5	10.0	1.2	1,225 (125)
SWS 8X14-A	8.5	8.0	9.0	14.0	1.6	2,156 (220)
SWS 10X17-A	11.0	10.0	11.0	17.0	1.6	3,724 (380)
SWS 12X21-A	14.0	12.0	13.5	21.0	2.0	6,147 (630)
SWS 14X23-A	16.0	14.0	15.5	23.0	2.0	9,310 (950)
SWS 16X26-A	18.0	16.0	17.5	26.0	2.0	12,740 (1,300)
SWS 18X27-A	20.0	18.0	18.5	27.0	2.0	19,600 (2,000)
SWS 20X32-A	23.0	20.0	22.0	32.0	2.3	28,420 (2,900)
SWS 22X35-A	25.0	22.0	24.0	35.0	2.3	39,200 (4,000)
SWS 24X38-A	26.0	24.0	26.0	38.0	2.3	49,000 (5,000)

SWS-K型 (頭付ボルト用 内径締め代ありタイプ)

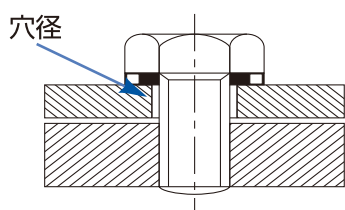

品番	適用穴径 最大φ	呼び径φ	内径φd	外径φD	厚みt	最大締め付けトルク N-cm (Kgf-cm)
SWS 3X10-K	3.5	3.0	2.8	10.3	1.3	392 (40)
SWS 4X11-K	4.5	4.0	3.8	11.3	1.3	784 (80)
SWS 5X12-K	5.5	5.0	4.8	12.3	1.3	1,225 (125)
SWS 6X13-K	6.5	6.0	5.8	13.3	1.3	2,156 (220)
SWS 8X16-K	8.5	8.0	7.8	16.3	1.3	2,156 (220)
SWS 10X18-K	10.5	10.0	9.8	18.3	1.3	3,724 (380)