



# SCA サイドカッタアーバ

## SIDE CUTTER ARBOR



### BT50


CODE	FIG	$\phi d$	L	L1	D	C	$\theta$	H	W	H1	H2	H3	C1
BT50-SCA25.4 -150	1	25.4	150	50	40	48.6	4°	30	6.35	21	32	25	40
			200			55.6							
			250			62.6							
			300			69.6							
BT50-SCA31.75 -150	1	31.75	150	50	46	54.6	4°	30	7.92	26	41	30	46
			200			61.6							
			250			68.6							
			300			75.6							
BT50-SCA38.1 -150	1	38.1	150	50	55	59.3	2°	30	9.52	31	46	36	55
			200			62.8							
			250			66.3							
BT50-SCA50.8 -100	2	50.8	100	-	72	-	-	40	12.7	45	55	48	72
			150			-							
			200			-							
BT50-SCA27 -150	1	27	150	50	40	48.6	4°	30	7	21	32	25	40
			200			55.6							
			250			62.6							
			300			69.6							
BT50-SCA32 -150	1	32	150	50	46	54.6	4°	30	8	26	41	30	46
			200			61.6							
			250			68.6							
			300			75.6							
BT50-SCA40 -150	1	40	150	50	55	59.3	2°	30	10	31	46	36	55
			200			62.8							
			250			66.3							
BT50-SCA50 -100	2	50	100	-	72	-	-	40	12	45	55	48	72
			150			-							
			200			-							

- カラー(5,10,20)ナット、キー付き。 Comes with collar (5,10,20) nut and key.
- 特殊サイズも注文により製作いたします。 Special size is available upon request.

## ST-SCA ストレートシャンク サイドカッタアーバ

### STRAIGHT SHANK SIDE CUTTER ARBOR

ミーリングチャックでご使用ください。

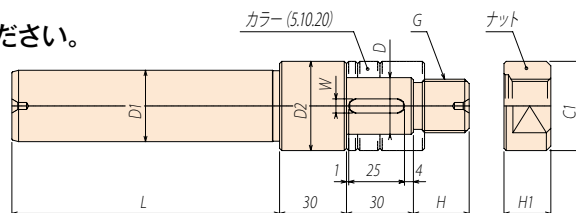

### ST32

CODE	$\phi D$	$\phi D1$	$\phi D2$	L	H	W	G
ST32-SCA15.875 - 30	15.875	32	26	120	16	3.18	M14 × P1.5
ST32-SCA22.225 - 30	22.225		34		21		M20 × P1.5
ST32-SCA25.4 - 30	25.4		40		25		M24 × P2.0

### ST42

CODE	$\phi D$	$\phi D1$	$\phi D2$	L	H	W	G
ST42-SCA15.875 - 30	15.875	42	26	120	16	3.18	M14 × P1.5
ST42-SCA22.225 - 30	22.225		34		21		M20 × P1.5
ST42-SCA25.4 - 30	25.4		40		25		M24 × P2.0

- カラー(5,10,20)ナット、キー付き。 Comes with collar (5,10,20) nut and key.
- 特殊サイズも注文により製作いたします。 Special size is available upon request.