



523~528

for parts or board attachment

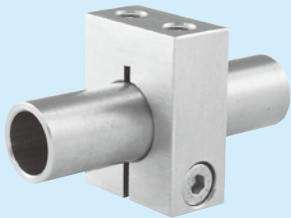

Screw tapped

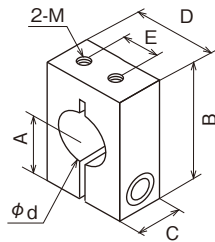

SUS 304	ϕ_d	A	B	C	D	E	2-M	Cap screw
PE4S523	8	13	25	10	20	9	M3	M4
PC4S523	9	13	25	10	20	9	M3	M4
PF4S523	10	13	25	10	20	9	M3	M4
PG4S523	12	16	30	12	23	10	M3	M4
PJ4S523	13	15	30	12	23	10	M3	M4

SUS 304	ϕ_d	A	B	C	D	E	2-M	Cap screw
PE4S524	8	14	30	10	20	10	M4	M4
PC4S524	9	14	30	10	20	10	M4	M4
PF4S524	10	14	30	10	20	10	M4	M4
PG4S524	12	16	30	12	23	12	M4	M4
PJ4S524	13	15	30	12	23	12	M4	M4
PN4S524	16	19	37	12	30	15	M4	M5

SUS 304	ϕ_d	A	B	C	D	E	2-M	Cap screw
PF4S525	10	14	30	10	20	10	M5	M4
PG4S525	12	14	30	12	23	12	M5	M4
PJ4S525	13	14	30	12	23	12	M5	M4
PN4S525	16	19	37	12	30	15	M5	M5
PL4S525*	19.05	20	43	16	32	15	M5	M5
PQ4S525	20	20	43	16	32	15	M5	M5


SUS 304	ϕ_d	A	B	C	D	E	2-M	Cap screw
PN4S526	16	18	40	12	30	15	M6	M5
PL4S526*	19.05	20	46	16	32	15	M6	M5
PQ4S526	20	20	46	16	32	15	M6	M5

SUS 304	ϕ_d	A	B	C	D	E	2-M	Cap screw
PL4S528*	19.05	20	46	16	32	15	M8	M5
PQ4S528	20	20	46	16	32	15	M8	M5


★ = ϕ_d tolerance is 0 / +0.021

533~538

for parts or board attachment

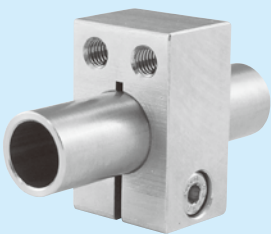

Screw tapped

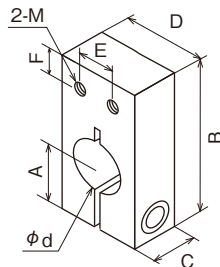

SUS 304	ϕ_d	A	B	C	D	E	F	2-M	Cap screw
PE4S533	8	13	30	12	20	9	5	M3	M4
PC4S533	9	13	30	12	20	9	5	M3	M4
PF4S533	10	13	30	12	20	9	5	M3	M4
PG4S533	12	15	32	16	20	10	5	M3	M4
PJ4S533	13	15	32	16	20	10	5	M3	M4

SUS 304	ϕ_d	A	B	C	D	E	F	2-M	Cap screw
PE4S534	8	13	30	12	20	10	5	M4	M4
PC4S534	9	13	30	12	20	10	5	M4	M4
PF4S534	10	13	30	12	20	10	5	M4	M4
PG4S534	12	15	32	16	20	10	5	M4	M4
PJ4S534	13	15	32	16	20	10	5	M4	M4
PN4S534	16	18	41	16	25	15	6	M4	M5

SUS 304	ϕ_d	A	B	C	D	E	F	2-M	Cap screw
PE4S535	8	13	30	12	20	10	5	M5	M4
PC4S535	9	13	30	12	20	10	5	M5	M4
PF4S535	10	13	30	12	20	10	5	M5	M4
PG4S535	12	15	32	16	20	10	5	M5	M4
PJ4S535	13	15	32	16	20	10	5	M5	M4
PN4S535	16	18	41	16	25	15	6	M5	M5
PL4S535*	19.05	20	46	19	32	15	6	M5	M5
PQ4S535	20	20	46	19	32	15	6	M5	M5

SUS 304	ϕ_d	A	B	C	D	E	F	2-M	Cap screw
PN4S536	16	18	41	16	25	15	6	M6	M5
PL4S536*	19.05	20	46	16	32	15	6	M6	M5
PQ4S536	20	20	46	19	32	15	6	M6	M5

SUS 304	ϕ_d	A	B	C	D	E	F	2-M	Cap screw
PL4S538*	19.05	20	46	19	32	15	6	M8	M5
PQ4S538	20	20	46	19	32	15	6	M8	M5

★ = ϕ_d tolerance is 0 / +0.021