


外形寸法図

(mm)

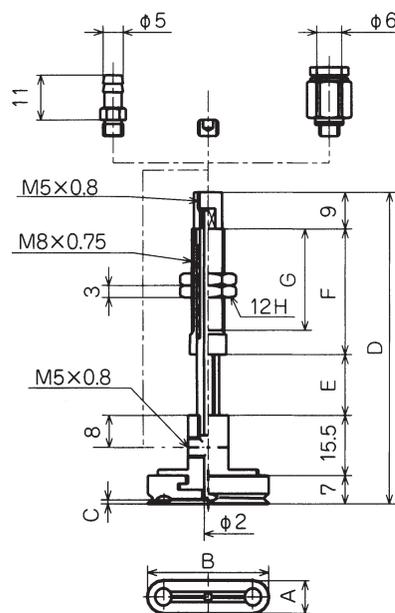

NAPWT/YH	A	B	C	D	E	F	G	F ¹	F ²	質量 (g)
NAPWT/YH-4×10-3	4	10	0.5	57.5	3	23	17	0.61	0.77	19.5
NAPWT/YH-4×10-10	4	10	0.5	64.5	10	23	17	0.61	1.17	20
NAPWT/YH-4×10-15	4	10	0.5	77	15	30.5	24.5	0.64	1.17	23
NAPWT/YH-4×20-3	4	20	0.5	57.5	3	23	17	0.61	0.77	20
NAPWT/YH-4×20-10	4	20	0.5	64.5	10	23	17	0.61	1.17	20.5
NAPWT/YH-4×20-15	4	20	0.5	77	15	30.5	24.5	0.64	1.17	23.5
NAPWT/YH-4×30-3	4	30	0.5	57.5	3	23	17	0.61	0.77	20.5
NAPWT/YH-4×30-10	4	30	0.5	64.5	10	23	17	0.61	1.17	21
NAPWT/YH-4×30-15	4	30	0.5	77	15	30.5	24.5	0.64	1.17	24
NAPWT/YH-5×10-3	5	10	0.5	57.5	3	23	17	0.61	0.77	19.5
NAPWT/YH-5×10-10	5	10	0.5	64.5	10	23	17	0.61	1.17	20
NAPWT/YH-5×10-15	5	10	0.5	77	15	30.5	24.5	0.64	1.17	23
NAPWT/YH-5×20-3	5	20	0.5	57.5	3	23	17	0.61	0.77	20
NAPWT/YH-5×20-10	5	20	0.5	64.5	10	23	17	0.61	1.17	20.5
NAPWT/YH-5×20-15	5	20	0.5	77	15	30.5	24.5	0.64	1.17	23.5
NAPWT/YH-5×30-3	5	30	0.5	57.5	3	23	17	0.61	0.77	20.5
NAPWT/YH-5×30-10	5	30	0.5	64.5	10	23	17	0.61	1.17	21
NAPWT/YH-5×30-15	5	30	0.5	77	15	30.5	24.5	0.64	1.17	24
NAPWT/YH-6×10-3	6	10	1	57.5	3	23	17	0.61	0.77	19.5
NAPWT/YH-6×10-10	6	10	1	64.5	10	23	17	0.61	1.17	20
NAPWT/YH-6×10-15	6	10	1	77	15	30.5	24.5	0.64	1.17	23
NAPWT/YH-6×20-3	6	20	1	57.5	3	23	17	0.61	0.77	20
NAPWT/YH-6×20-10	6	20	1	64.5	10	23	17	0.61	1.17	20.5
NAPWT/YH-6×20-15	6	20	1	77	15	30.5	24.5	0.64	1.17	23.5
NAPWT/YH-6×30-3	6	30	1	57.5	3	23	17	0.61	0.77	20.5
NAPWT/YH-6×30-10	6	30	1	64.5	10	23	17	0.61	1.17	21
NAPWT/YH-6×30-15	6	30	1	77	15	30.5	24.5	0.64	1.17	24
NAPWT/YH-8×20-3	8	20	1	57.5	3	23	17	0.61	0.77	20
NAPWT/YH-8×20-10	8	20	1	64.5	10	23	17	0.61	1.17	20.5
NAPWT/YH-8×20-15	8	20	1	77	15	30.5	24.5	0.64	1.17	23.5
NAPWT/YH-8×30-3	8	30	1	57.5	3	23	17	0.61	0.77	20.5
NAPWT/YH-8×30-10	8	30	1	64.5	10	23	17	0.61	1.17	21
NAPWT/YH-8×30-15	8	30	1	77	15	30.5	24.5	0.64	1.17	24

注意. 表中記号F¹は0ストローク時、F²はフルストローク時のバネ荷重(N)を表します。