



外形寸法図


(mm)

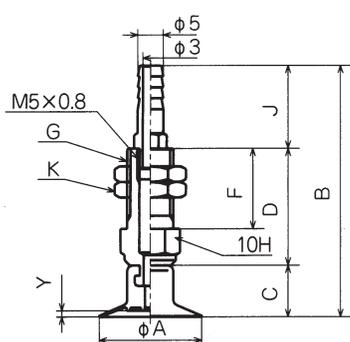


PATK-10A/15A/20A  
10B/15B/20B

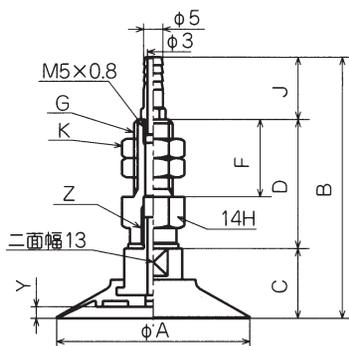


PATK-25/30/40/50

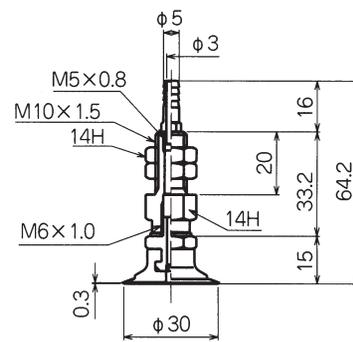


PATK-30B

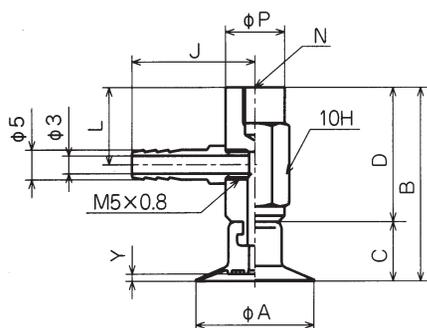

PAYK-10A/15A/20A  
10B/15B/20B

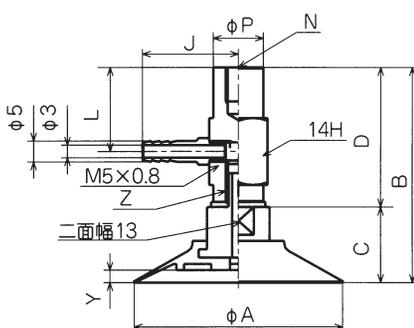

PAYK-25/30/40/50

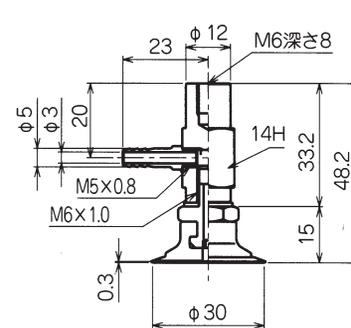

PAYK-30B

PATK	A	B	C	D	F	G	J	K	Y	Z	質量 (g)
PATK-10A	0	41	7.5	22.5	15.5	M9×1.0	11	12H	0.6	/	15
PATK-10B	0	41	7.5	22.5	15.5	M9×1.0	11	12H	0.3		15
PATK-15A	5	41	7.5	22.5	15.5	M9×1.0	11	12H	0.9		15
PATK-15B	5	41	7.5	22.5	15.5	M9×1.0	11	12H	0.5		15
PATK-20A	20	43.5	10	22.5	15.5	M9×1.0	11	12H	1.2		16
PATK-20B	20	42.5	9	22.5	15.5	M9×1.0	11	12H	0.8		16
PATK-25	25	62.2	18	3.2	20	M10×1.5	11	14H	1.5	M6×1.0	54
PATK-30	30	62.2	18	33.2	20	M10×1.5	11	14H	1.8	M6×1.0	55
PATK-40	40	62.2	18	33.2	20	M10×1.5	11	14H	2.4	M6×1.0	55
PATK-50	50	62.2	18	33.2	20	M10×1.5	11	14H	3	M6×1.0	56

PAYK	A	B	C	D	J	L	N	P	Y	Z	質量 (g)
PAYK-10A	10	30	7.5	22.5	16	13	M4深さ6	10	0.6	/	16
PAYK-10B	10	30	7.5	22.5	16	13	M4深さ6	10	0.3		16
PAYK-15A	15	30	7.5	22.5	16	13	M4深さ6	10	0.9		16
PAYK-15B	15	30	7.5	22.5	16	13	M4深さ6	10	0.5		16
PAYK-20A	20	32.5	10	22.5	16	13	M4深さ6	10	1.2		17
PAYK-20B	20	31.5	9	22.5	16	13	M4深さ6	10	0.8		17
PAYK-25	25	51.2	18	33.2	18	20	M6深さ8	12	1.5	M6×1.0	54
PAYK-30	30	51.2	18	33.2	18	20	M6深さ8	12	1.8	M6×1.0	55
PAYK-40	40	51.2	18	33.2	18	20	M6深さ8	12	2.4	M6×1.0	55
PAYK-50	50	51.2	18	33.2	18	20	M6深さ8	12	3	M6×1.0	56

