

# Bellows pad / PBG

## How to order

PBG - ① 10A - ② N

① Pad diameter (mm)

10A	φ10
15A	φ15
20	φ20
30	φ30
40	φ40
50	φ50
75	φ75
110	φ110
150	φ150

② Pad rubber material

N	NBR(Nitrile rubber)
S	Silicone rubber
U	Urethane rubber
F	Fluorine rubber
NE	Conductive NBR(Nitrile rubber)
SE	Conductive Silicone rubber

Note) Please consult with us for other material.

## Pad standard specifications


Symbol	Material	Hardness(Hs)	Ambient temperature	Color	Volume resistivity Note1・2
N	NBR(Nitrile rubber)	A55/S	-26 ~ 120°C	Black	-
S	Silicone rubber	A55/S	-60 ~ 250°C	White	-
U	Urethane rubber	A55/S	-20 ~ 75°C	Blue	-
F	Fluorine rubber	A70/S	-10 ~ 230°C	Black with white dot	-
NE	Conductive NBR(Nitrile rubber)	A70/S	-26 ~ 120°C	Black with blue dot	10 <sup>2</sup> ~ 10 <sup>3</sup> Ω・cm
SE	Conductive Silicone rubber	A55/S	-60 ~ 250°C	Black with red dot	10 <sup>2</sup> ~ 10 <sup>4</sup> Ω・cm

Note1) Volume resistivity shows conductivity, resistance value is per cm<sup>3</sup>.

Note2) It is the measured value of in our designated test piece.

## Dimensions

Unit : mm <inch>

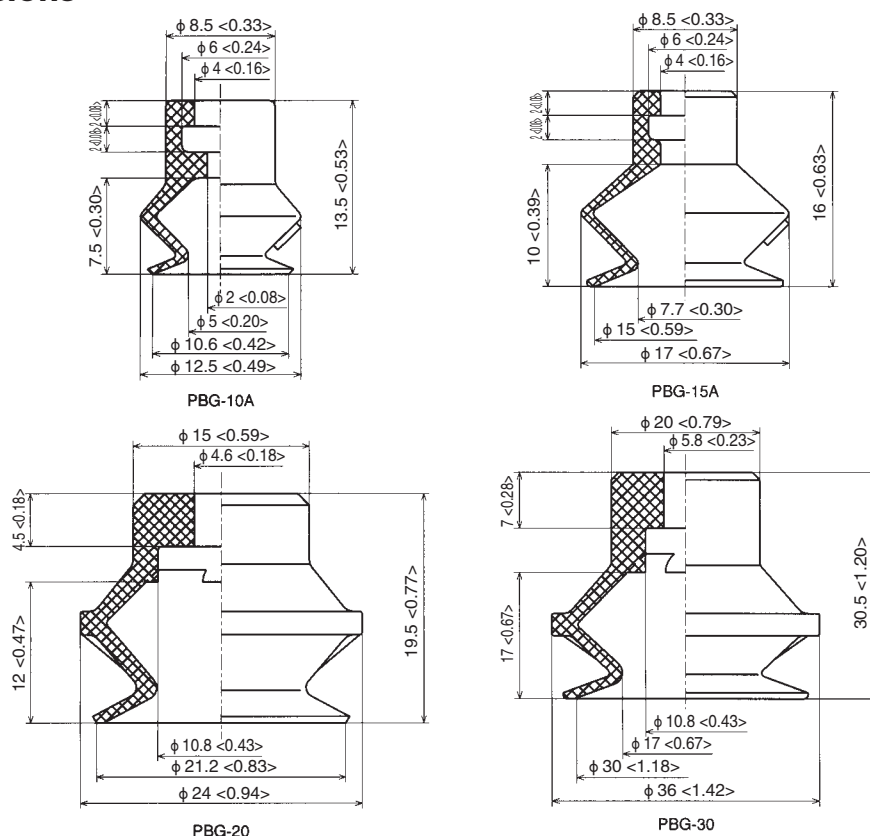

Suction pads