




O型フック

Oval Hook

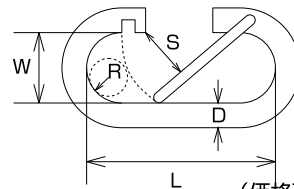

材質：ステンレス SUS304


(価格改定日 H20.1) (mm)

品番	D	L	W	S	R	weight (g)	参考使用荷重 (kgf)	(kN)	価格(円)/個	入数	コード No.
MO-3	3	22	8	6	2.5	3	5	0.05	380	20	2102
MO-4	4	30	10	7	3.5	8	15	0.15	490	20	1942
MO-5	5	41	16	12	4.5	17	20	0.20	600	20	1943
MO-6	6	52	21	15	7	30	30	0.29	770	20	1944
MO-8	8	57	22	16	8	59	50	0.49	1,100	20	1945
MO-10	10	61	24	18	7.5	103	120	1.18	1,730	10	1946



O型フック (ロープ用)

Oval Hook For Rope

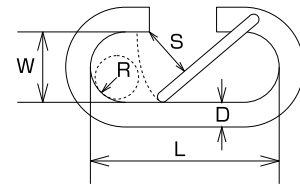

材質：ステンレス SUS304


(価格改定日 H20.1) (mm)

品番	D	L	W	S	R	weight (g)	参考使用荷重 (kgf)	(kN)	価格(円)/個	入数	コード No.
MO-2R	2	15	5.5	5	2	1	2	0.02	280	20	2179
MO-2.5R	2.5	18	6.5	6	2.5	2	3	0.03	320	20	2180
MO-5R	5	41	16	11	5	17	16	0.16	600	20	2055
MO-6R	6	52	21	15	7	30	20	0.20	770	20	2056



Dフック

Spring Snap "D"

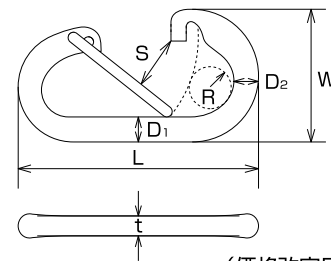

材質：ステンレス SUS304


(価格改定日 H20.1) (mm)

品番	D ₁	D ₂	L	W	S	R	t	weight (g)	参考使用荷重 (kgf)	(kN)	価格(円)/個	入数	コード No.
DF-4	4.6	4	42	23	9	3.5	3	8	20	0.20	550	20	1950
DF-5	5.4	5	52.5	30	13	5	4	16	30	0.29	660	20	1473
DF-6	7.0	6	64	34	14	5.5	4.5	29	70	0.69	830	20	1474
DF-8	8.7	8	80	45	18	7.5	6.4	64	100	0.98	1,100	20	1478
DF-10	11.5	10	105	58	25	10	7.2	133	150	1.47	1,760	10	1479



マガタマフック

"MAGATAMA" Spring Snap

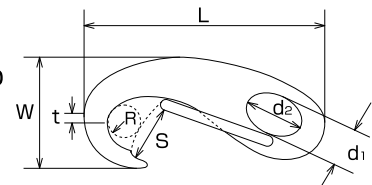

材質：ステンレス SUS304

(価格改定日 H20.1) (mm)

品番	L	W	S	R	d ₁	d ₂	t	weight (g)	参考使用荷重 (kgf)	(kN)	価格(円)/個	入数	コード No.
MH-S1	32	17	9	2.5	5	7	4	7	3	0.03	500	20	2080
MH-0	40	20	7	3	5	9	4.5	13	5	0.05	640	20	1284
MH-1	50	24	11	4.5	7	10.5	5	20	20	0.20	750	20	137
MH-2	69	30	12	4.5	10	16	7	48	40	0.39	1,100	20	138
MH-3	95	45	13	6	15	21.5	9	133	60	0.59	1,700	10	663

