
 


## ソケット

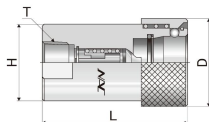


品番	重量(g)	接続形状	寸法 (mm)		
			T	L	H
CHP02S	148	Rc $\frac{1}{4}$ "	49	30	二面19/φ24
CHP03S	234	Rc $\frac{3}{8}$ "	60	34.5	二面23/φ28.5
CHP04S	498	Rc $\frac{1}{2}$ "	72	44	二面35/φ38.5
CHP06S	470	Rc $\frac{3}{4}$ "	72	44	二面35/φ38.5
CHP08S	1044	Rc1"	93	58.5	二面46/φ52
CHP10S	2798	Rc1 $\frac{1}{4}$ "	138	88	二面58/φ64
CHP12S	2728	Rc1 $\frac{1}{2}$ "	138	88	二面58/φ64
CHP16S	7290	Rc2"	198	123	二面80/φ90

## プラグ



品番	重量(g)	接続形状	寸法 (mm)			
			L	S	C	ℓ
CHP02P	40	Rc $\frac{1}{4}$ "	32	19	20.5	17.5
CHP03P	66	Rc $\frac{3}{8}$ "	38	23	25	22.5
CHP04P	122	Rc $\frac{1}{2}$ "	44	29	32	27.5
CHP06P	144	Rc $\frac{3}{4}$ "	50	32	35	27.5
CHP08P	364	Rc1"	61		二面41/φ47	36
CHP10P	884	Rc1 $\frac{1}{4}$ "	80		二面58/φ64	58
CHP12P	812	Rc1 $\frac{1}{2}$ "	80		二面58/φ64	58
CHP16P	3330	Rc2"	115		二面90/φ100	83

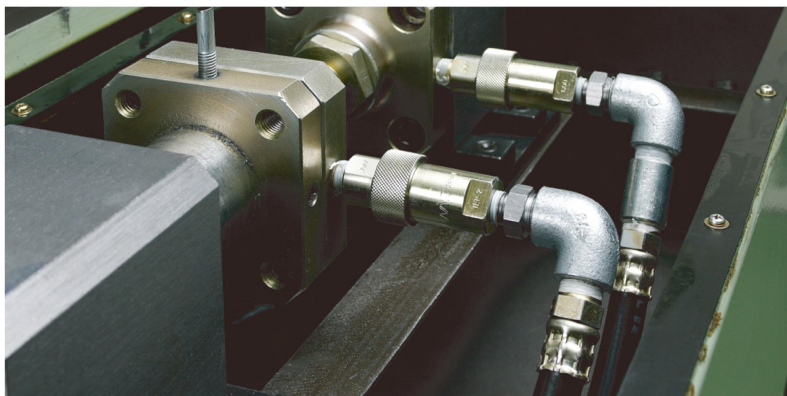

\*ご使用前に、クイックカップリングの取扱上の注意を必ずお読み下さい。