


UNF/UNFS/UNFA U - shaped Pull

Recommendation

WEB Selection Tool WEB CAD Download SUS Stainless steel

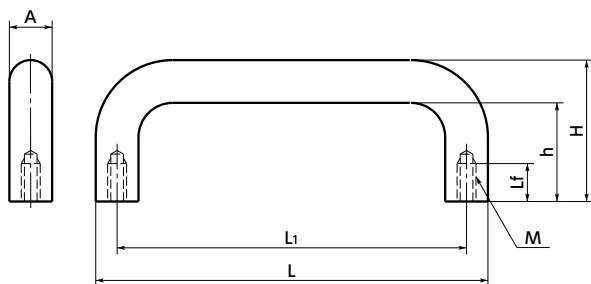

- Types, materials and surface treatment can be selected according to the product code.

Product Code	Type	Material and Surface Treatment
UNF-CR	Standard Type H=37	Made of Steel Chrome Plating
UNFS	Standard Type H=37	Made of Stainless Steel Barrel Polishing
UNFS-KF	Standard Type H=37	Made of Stainless Steel Antibacterial
UNFA-BF	Standard Type H=37	Made of Aluminum Buffing
UNFA-BK	Standard Type H=37	Made of Aluminum Electrostatic Coating
UNF-H-CR	High Position Type H=45	Made of Steel Chrome Plating
UNFS-H	High Position Type H=45	Made of Stainless Steel Barrel Polishing
UNF-SH-CR	SEMI Standards Compliance Type H=60	Made of Steel Chrome Plating
UNFS-SH	SEMI Standards Compliance Type H=60	Made of Stainless Steel Barrel Polishing

- UNFS-KF** is the antibacterial specifications. It is highly antibacterial, mold-proof and algae-proof.
→ P.266

Material/Finish

RoHS Compliant

	UNF-CR	UNFS	UNFS-KF	UNFA-BF	UNFA-BK
Main body	SS330 Chrome Plating	SUS304 Barrel Polishing	SUS304 Antibacterial	Aluminum Alloy Buffing	Aluminum Alloy Electrostatic Coating (Matte Black)

UNF-CR Standard Type / Made of Steel										UNFS Standard Type / Made of Stainless Steel		Unit : mm
Part Number Steel	Part Number Stainless steel	L1	A	H	h	L	Lf	M	Allowable load*1 (N)	Mass (g)		
UNF-80-CR	UNFS-80	80	10	37	27	90	10	M5	1000	76		
UNF-100-CR	UNFS-100	100	10	37	27	110	10	M5	1000	88		
UNF-110-CR	UNFS-110	110	10	37	27	120	10	M5	1000	95		
UNF-120-CR	UNFS-120	120	10	37	27	130	10	M5	1000	101		
UNF-125-CR	UNFS-125	125	10	37	27	135	10	M5	1000	103		
UNF-160-CR	UNFS-160	160	10	37	27	170	10	M5	1000	125		
UNF-200-CR	UNFS-200	200	10	37	27	210	10	M5	1000	150		
UNF-250-CR	UNFS-250	250	10	37	27	260	10	M5	1000	180		

*1 Allowed load for a person.

UNFS-KF Standard Type / Made of Stainless Steel / Antibacterial Specification										Unit : mm
Part Number Stainless steel	L1	A	H	h	L	Lf	M	Allowable load*1 (N)	Mass (g)	
UNFS-80-KF	80	10	37	27	90	10	M5	1000	76	
UNFS-100-KF	100	10	37	27	110	10	M5	1000	88	
UNFS-125-KF	125	10	37	27	135	10	M5	1000	103	

*1 Allowed load for a person.

Cleanroom Wash & Packaging → P.792

Laser Marking → P.806

S.S. & AI only/ Add'l charge

S.S. & AI. only/ Add'l charge