

- For slide position adjustment, etc.
- Use the same thread fitting length for both-side hexagon stud bolt **SHS**.

● Material/Finish




	STB
Joint Nut SjN	SUM22L Ferrosoferric Oxide Film (Black)
Hex Stud Bolts SHS	S45C (hardness: 35 - 45 HRC) Ferrosoferric Oxide Film (Black)
Nut	SS400 Ferrosoferric Oxide Film (Black)

Unit : mm

Part Number	M (Coarse)		min.L	E	A	sw	H	H1	Mass (g)
	Nominal of Thread	Pitch							
STB-M4	M4	0.7	64	8	7.5	7	3.2	2.4	16
STB-M6	M6	1	89	12	10	10	5	3.6	40
STB-M8	M8	1.25	116	16	13	13	6.5	5	115
STB-M10	M10	1.5	143	20	16	17	8	6	185
STB-M12	M12	1.75	171	24	20	19	10	7	290
STB-M16	M16	2	217	32	21	24	13	10	600

- For detailed dimensions, refer to hexagon stud bolt **SHS** (→ P.xxxx) and joint nut **SjN** (→ P.xxxx).

● Usage example

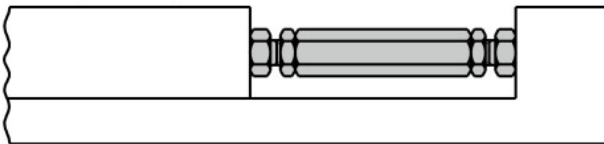

● Part number specification

STB-M6



Cleanroom Wash & Packaging → P.xxxx Not Available	Screw Length Adjustment → P.xxxx Not Available	Vibration Resistant → P.xxxx Available / Add'l charge	Laser Marking → P.xxxx Please feel free to contact us
--	---	--	--