


# GSS Stainless Steel Fixing Grip



WEB Selection Tool

WEB CAD Download

SUS Stainless steel

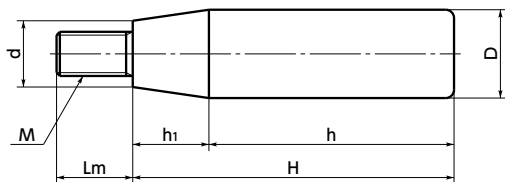

- All stainless steel grip superior in corrosion resistance and strength

- Material/Finish

RoHS Compliant

	GSS
Main body	SUS304

Unit : mm

Part Number	D	M	Lm	d	H	h	h1	Mass (g)
<b>GSS-5</b>	10	M5	6	8	40	30	10	25
<b>GSS-6</b>	13	M6	7	10	50	37	13	50
<b>GSS-8</b>	16	M8	8	12	64	49	15	100
<b>GSS-10</b>	20	M10	10	15	70	50	20	150
<b>GSS-12</b>	25	M12	13	18	100	70	30	370

- Usage example  
In combination with a stainless steel handwheel  
**HSM** (→ P.400).



- Part number specification

**GSS-5**



Cleanroom Wash & Packaging → P.792

Vibration Resistant → P.795

Laser Marking → P.806

Modification of Shaft Hole Diameter → P.800

Available / Add'l charge

Available / Add'l charge

Available / Add'l charge

Not Available