


# SSTS Hexalobular Socket Head Cap Screws with Special Low Profile



WEB Selection Tool  
 WEB CAD Download  
 Protrusion  
 SUS Stainless steel

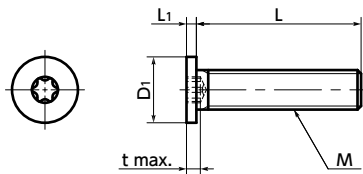

● Part number specification

## SSTS-M5-12



Order in number of packs.  
The minimum order quantity is 1 piece. → P.794

- The head height for all screws is 1.5 mm or less.
  - Intended for reducing the size of devices and applications with limited overhead space.
  - The hexalobular\* shape can withstand high tightening torque. → P.712
- \*The hexalobular shape is prescribed by JIS B 1015 : 2008 (ISO 10664 : 2005) "Hexalobular internal driving feature for bolts and screws"

- Install and remove by using **SKX** Specialty Hexalobular Key. → P.715



● Application

Reducing the size of equipment and devices

● Material/Finish

RoHS Compliant

	SSTS
Main Body	SUSXM7 (S.S. grade : A2)
Strength Class	A2-50

Unit : mm

Part Number	M	L							D1	L1	Applicable wrench	Hexalobular Socket No.	t	Max. Torque (N·m)	Mass (g)	
<b>SSTS-M2</b>	M2	4	5	6	8				4	1.2	SKX-5	5	0.9	0.18	0.11 - 0.19	
<b>SSTS-M2.5</b>	M2.5	4	5	6	8				5	1.3	SKX-6	6	1	0.36	0.23 - 0.35	
<b>SSTS-M3</b>	M3		5	6	8	10			6	1.3	SKX-8	8	1.1	0.65	0.4 - 0.61	
<b>SSTS-M4</b>	M4			6	8	10	12		8	1.5	SKX-10	10	1.5	1.5	0.89 - 1.3	
<b>SSTS-M5</b>	M5			6	8	10	12	16	9	1.5	SKX-15	15	1.8	3.1	0.73 - 2	
<b>SSTS-M6</b>	M6				8	10	12	16	20	10	1.5	SKX-20	20	2.1	5.3	1.6 - 3.8
<b>SSTS-M8</b>	M8				8	10	12	16	20	13	1.5	SKX-25	25	2.4	12	3 - 6.7

Part Number	Qty*1 per pack
<b>SSTS-M2</b>	10
<b>SSTS-M2.5</b>	10
<b>SSTS-M3</b>	10
<b>SSTS-M4</b>	10
<b>SSTS-M5</b>	10
<b>SSTS-M6</b>	10
<b>SSTS-M8</b>	10

\*1 The minimum order quantity is 1 piece. → P.794

Individual Sales → P.794  
 Cleanroom Wash & Packaging → P.792  
 Screw Length Adjustment → P.796  
 Vibration Resistant → P.795  
 Modification process for captive use → P.791

Available / Add'l charge   Available / Add'l charge   Available / Add'l charge   Available / Add'l charge   Available / Add'l charge