


SNBS(INCH) Socket Button Head Cap Screws - Inch Thread



WEB Selection Tool WEB CAD Download SUS Stainless steel

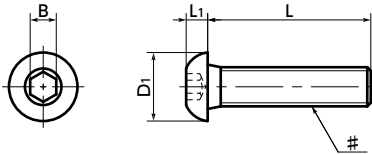

● Material/Finish ✔ RoHS Compliant

SNBS(INCH)	
Main Body	Stainless Steel (Grade : A2)
Strength Class	A2-50

● Part number specification

SNBS- # 4-40 - 1/4



Order in number of packs.
The minimum order quantity is 1 piece. → P.794

- Socket button head cap screws with inch thread.
- ANSI B18.3 compliance.
- Install and remove by using **SKH(INCH)** Specialty Key. → P.703
- Also, products with special specifications such as dimensions, shapes, materials, surface treatments, cleanroom washing and special packaging are available. → P.544



● Application

Equipment and devices using inch screw specifications

Unit : Inch

Part Number 1	# Nominal of Thread	L 2								D1	L1	B	Mass (g)	
		3/16	1/4	5/16	3/8	1/2	5/8	3/4	7/8					
SNBS- # 4-40	No.4-40UNC	3/16	1/4	5/16	3/8	1/2				0.213	0.059	1/16	0.35 - 0.65	
SNBS- # 5-40	No.5-40UNC		1/4		3/8	1/2				0.238	0.066	5/64	0.53 - 0.85	
SNBS- # 6-32	No.6-32UNC		1/4	5/16	3/8	1/2	5/8	3/4		0.262	0.073	5/64	0.67 - 1.4	
SNBS- # 8-32	No.8-32UNC		1/4		3/8	1/2	5/8	3/4		0.312	0.087	3/32	1.1 - 2.2	
SNBS- # 10-24	No.10-24UNC		1/4		3/8	1/2	5/8	3/4	7/8	1	0.361	0.101	1/8	1.5 - 3.6
SNBS- # 10-32	No.10-32UNF		1/4		3/8	1/2	5/8	3/4	7/8	1	0.361	0.101	1/8	1.5 - 3.8
SNBS-1/4-20	1/4-20UNC				3/8	1/2	5/8	3/4	7/8	1	0.437	0.132	5/32	3.3 - 6.4

● All dimensions are in inches.

Part Number	Qty*1 per pack
SNBS- # 4-40	10
SNBS- # 5-40	10
SNBS- # 6-32	10
SNBS- # 8-32	10
SNBS- # 10-24	10
SNBS- # 10-32	10
SNBS-1/4-20	10

*1 The minimum order quantity is 1 piece. → P.794

Individual Sales → P.794	Cleanroom Wash & Packaging → P.792	Screw Length Adjustment → P.796	Vibration Resistant → P.795	Modification process for captive use → P.791
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available