

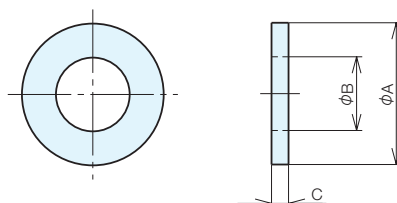
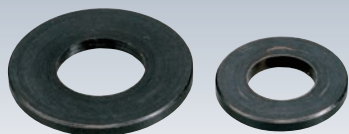
RoHS Compliant

ERON®

No.E-418

Flat Washers

Material SUM22 **Heat Treatment** HRC30 ± 5 heat treatment

 
Surface Treatment Blackened


Specifications

Order No.	No.	Compatible Bolts	A	B	C	Weight (g)	
50581	WF 4	M4	12	4.5	2	2	
50582	WF 6	M6	16	7	2.5	3	
19567	WF 8	M8	19	9	3	5	
03288	WF10	M10	22	11	3	7	
03289	WF12	M12	25	13	3	8	
03290	WF14	M14	28	15	3	11	
03291	WF16	M16	35	17	3	18	
03292	WF18	M18	38	19	3.5	23	
03293	WF20	M20	42	21	4	30	
03294	WF22	M22	44	23	4	34	
03295	WF24	M24	50	27	5	56	

Reference Pages

Flat washers (thick washers)



Base Elements

Clamp Units

Clamping Parts

Machine Vises

Drilling Vises

Vibration Isolation

Surface Plates and Measurement Instruments

Index