



Attachment Clamps

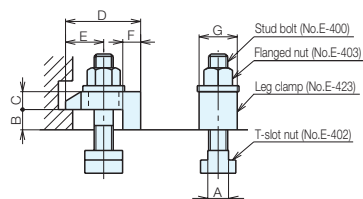

BCS-14B, CBCS-16B, C, G, HBCS-18B, C, F, G, H

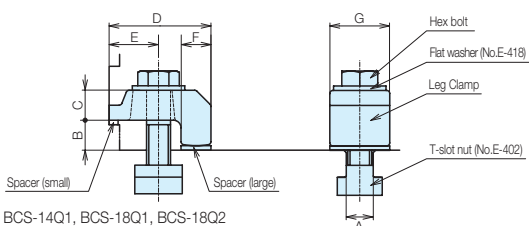

BCS-14Q1, BCS-18Q1, BCS-18Q2

Specifications

(2 pieces per set)

Compatible Groove Width	Compatible Models	Order No.	No.	A	B	C	D	E	F	G	Leg Clamp	T-Slot Nut	Flanged Nut	Stud Bolt
14	LTCV100(S,H,SH),LTCV125(S,H,SH), LTCV160(S,H,SH,TH),LTCV200(S,H,SH,TH), LTFV100Q,LT150MC,LTM150WL,LT5AU100(F,M,FM)	35854	BCS-14B	13.5	17	15	63	27-37	15	32	LCMC121	TNM1412	FNM0012	BM01275
14	LTFV75,LT100MC,LTM100WL,LTAW100,LT5AU-75(F,FM)	43967	BCS-14C	13.5	12	15	55	26-31	15	32	LCMC122	TNM1412	FNM0012	BM01275
14	LTFV75, LT5AU-75(F,FM)	97234	BCS-14Q1	13.5	12	20	63	23-38	15	32	Dedicated clamp & spacer	TNM1412K	Hex bolt M12×60 & flat washer WF12	
16	LTCV100(S,H,SH),LTCV125(S,H,SH), LTCV160(S,H,SH,TH),LTCV200(S,H,SH,TH),LTFV100Q, LTFV125Q,LTFFH125Q,LT150MC,LTM150WL,LT5AU100(F,M,FM)	35856	BCS-16B	15.3	17	15	63	28-36	15	32	LCMC161	TNM1614	FNM0014	BM14100
16	LTCV100(S,H,SH),LTCV125(S,H,SH), LTCV160(S,H,SH,TH),LTCV200(S,H,SH,TH),LTFV100Q, LTFV125Q,LTFFH125Q,LT150MC,LTM150WL,LT5AU100(F,M,FM)	35857	BCS-16C	15.3	17	15	95	41-71	15	32	LCMC162	TNM1614	FNM0014	BM14100
16	LTFV150Q,LTFFH150Q,LTFV175Q,LTFFH175Q	43968	BCS-16G	15.3	20	20	80	32-43	25	45	LCMC164	TNM1614	FNM0014	BM14100
16	LTFV75,LT100MC,LTM100WL,LTAW100	59333	BCS-16H	13.5	12	15	55	26-31	15	32	LCMC122	TNM1612	FNM0012	BM01275
18	LTCV100(S,H,SH),LTCV125(S,H,SH), LTCV160(S,H,SH,TH),LTCV200(S,H,SH,TH),LTFV100Q, LTFV125Q,LTFFH125Q,LT150MC,LTFW100,LTM150WL	35862	BCS-18B	17	17	15	63	28-36	15	32	LCMC161	TNM1816	FNM0016	BM16100
18	LTCV100(S,H,SH),LTCV125(S,H,SH), LTCV160(S,H,SH,TH),LTCV200(S,H,SH,TH),LTFV100Q, LTFV125Q,LTFFH125Q,LT150M,LTM150WL,LT5AU100(F,M,FM)	35863	BCS-18C	17	17	15	95	41-71	15	32	LCMC162	TNM1816	FNM0016	BM16100
18	LTFV150Q,LTFFH150Q,LTFV175Q,LTFFH175Q	43969	BCS-18G	17	20	20	80	32-43	25	45	LCMC164	TNM1816	FNM0016	BM16100
18	LTFV75,LT100MC,LTM100WL,LTAW100	59334	BCS-18H	17	12	15	55	26-31	15	32	LCMC122	TNM1812	FNM0012	BM01275
18	LTCV100(S,H,SH),LTCV125(S,H,SH), LTCV160(S,H,SH,TH),LTCV200(S,H,SH,TH),LTFV100Q, LTFV125Q,LTFFH125Q,LT5AU100(F,M,FM),LTFV125H	86725	BCS-18Q1	17	17	20	68	25-33	20	40	Dedicated clamp and spacer	TNM1816K	Hex bolt M16×70 & flat washer WF16	
18	LTFV150Q,LTFFH150Q,LTFV175Q,LTFFH175Q,LTFV150H	86726	BCS-18Q2	17	20	20	68	25-33	20	40	Dedicated clamp and spacer	TNM1816K	Hex bolt M16×75 & flat washer WF16	

Base Elements

Clamp Units

Clamping Parts

Machine Vises

Drilling Vises

Vibration Isolation

Surface Plates and Measurement Instruments

Index