


## ■口金

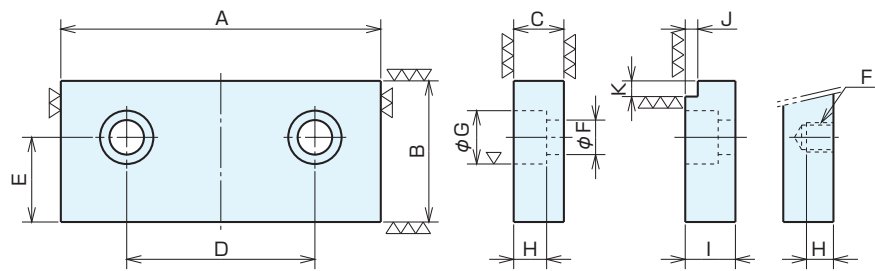

## サイズ表


適合機種	A	B	C	D	E	F	G	H	J	K	ネジ径	I
LTCV100(S,H,SH)	102	45	12	60	27	11	18	7	4	5	M10	16
LTCV125(S,H,SH)	125	50	12	75	30	11	18	7	4	5	M10	16
LTCV160(S,H,SH,TH)	160	60	12	90	35	11	18	7.5	5	6	M10	19
LTCV200(S,H,SH,TH)	200	70	12	130	40	11	18	7	5	6	M10	19
LTFV75	76	32	14	46	18	M8	-	-	4	5	M 8	14
LTFV100Q	102	45	16	60	27	11	18	10.5	4	5	M10	16
LTFV・LTFH125Q	125	50	16	75	30	11	18	10.5	4	5	M10	16
LTFV・LTFH150Q	150	60	19	90	35	13	19	12.5	5	6	M12	19
LTFV・LTFH175Q	175	70	19	90	45	13	19	12.5	5	6	M12	19
LT630JV	160	75	19	85	35	14	20	13	5	6	M12	19
LT100M,LT100MC,LT100SP,LTM100WL	101	32	14	60	18	9	14	9	3.5	4	M 8	14
LT125M,LT125SP	126	38	19	77	21	13	19	13	3.5	4	M12	19
LT150M,LT150MC,LT-HPD150	151	44.2	19	100	24	13	19	13	4.5	5	M12	19
LT200M	202	57	29	119	31	17	25	17	5.5	6	M16	29
LT250M	253	75.5	34	140	41	17	25	17	5.5	6	M16	34
LT150L,LTM150WL	151	44.2	14	100	24	11	18	10.5	4.5	5	M10	14
LT-HPD80E	207	57	29	121	31	17.5	25	17	5.5	6	5/8-11UNC	29
LT150WL	151.6	47.7	18.7	98.4	23.9	13.5	20	13.5	4.7	4.7	1/2-13UNC	18.7
LTH3P-125	129	54	19	80	25	11	18	10.5	6	7	M10	19
LTH3P-150S	156	57	14	90	25	11	18	10.5	6	7	M10	14

## 仕様・価格表

2枚1組

適合機種	標準口金			ステップ口金		
	オーダー No.	No.	価 格	オーダー No.	No.	価 格
LTCV100(S,H,SH),LT5AU-100F(M)	78206	LTCV100-JA	13,600	30336	LTF-100SJ	15,700
LTCV125(S,H,SH)	78207	LTCV125-JA	19,300	30337	LTF-125SJ	20,900
LTCV160(S,H,SH,TH)	78208	LTCV160-JA	23,200	78209	LTCV160-SJ	26,600
LTCV200(S,H,SH,TH)	84582	LTCV200-JA	33,900	84583	LTCV200-SJ	38,700
LTFV75	62537	LTF-75JA	11,400	62538	LTF-75SJ	13,600
LTFV100Q	30332	LTF-100JA	15,000	30336	LTF-100SJ	15,700
LTFV・LTFH125Q	30333	LTF-125JA	21,200	30337	LTF-125SJ	20,900
LTFV・LTFH150Q	30334	LTF-150JA	24,200	30338	LTF-150SJ	27,100
LTFV・LTFH175Q	30335	LTF-175JA	34,700	30339	LTF-175SJ	38,700
LT630JV	19772	LT630JV-JA	25,300	19911	LT630JV-SJ	37,600
LT100M,LT100MC,LT100SP,LTM100WL	32161	LT100M-JA	11,400	32162	LT100M-SJ	13,600
LT125M,LT125SP	32163	LT125M-JA	16,000	32164	LT125M-SJ	18,300
LT150M,LT150MC,LT-HPD150	32165	LT150M-JA	18,300	32166	LT150M-SJ	20,600
LT200M	32167	LT200M-JA	34,300	32168	LT200M-SJ	36,700
LT250M	32169	LT250M-JA	38,800	32170	LT250M-SJ	55,000
LT150L,LTM150WL	55470	LT150L-JA	18,300	55471	LT150L-SJ	20,600
LT-HPD80E	00369	LT-80JA	34,300	00364	LT-80SJ	36,700
LT150WL	-	-	-	18975	LT150WL-SJ	24,600
LTH3P-125	10840	LTH3P-125JA	16,000	10772	LTH3P-125SJ	18,300
LTH3P-150S	69385	LTH3P150S-JA	18,300	69386	LTH3P150S-SJ	20,600

## 使用例

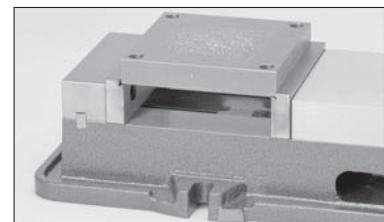ベース  
エレメント

補助ベース

ローテイング  
エレメントクランプ  
ユニットクランプピン  
パーツメカニカル  
パーツモジュラー  
シグシステムブロック  
ビルド  
シグシステム

マシンバイス

ボール盤  
バイス定盤  
測定機器

横バイス

クランプ

諸工具

作業台

技術資料

索引