RoHS対応 **NEW**

EXTENSION BAR


No.E-659T

## Q-ロックエレメントサイド操作タイプ延長工具

材質 本体：S45C 六角ジョイント部：SCM440

熱処理 六角ジョイント部：焼入 HRC52～58

ジョイントバー（両端面）：高周波焼入HRC36～44

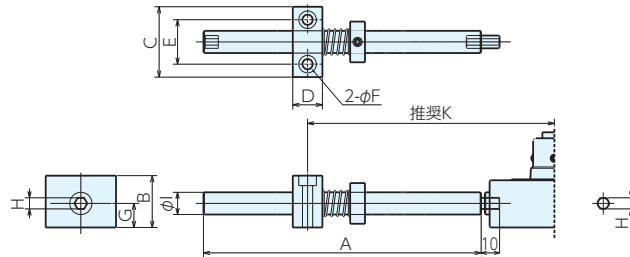

## 仕様・価格表

オーダーNo.	No.	適合Qロックエレメント	A	B	C	D	E	F	G	H	I	質量g	価格
96495	QLTS26-E100	QLTS26	100	28	38	16	24	6	13	6	12	250	5,750
96496	QLTS26-E125		125	28	38	16	24	6	13	6	12	270	5,750
96497	QLTS26-E150		150	28	38	16	24	6	13	6	12	290	5,750
96498	QLTS26-E175		175	28	38	16	24	6	13	6	12	310	5,750
96499	QLTS26-E200		200	28	38	16	24	6	13	6	12	330	5,750
96500	QLTS26-E225		225	28	38	16	24	6	13	6	12	350	5,750
96501	QLTS26-E250		250	28	38	16	24	6	13	6	12	380	5,750
96502	QLTS26-E275		275	28	38	16	24	6	13	6	12	400	5,750
96503	QLTS26-E300		300	28	38	16	24	6	13	6	12	420	6,000
96504	QLTS26-E325		325	28	38	16	24	6	13	6	12	440	6,000
96505	QLTS26-E350		350	28	38	16	24	6	13	6	12	460	6,000
96506	QLTS26-E375		375	28	38	16	24	6	13	6	12	480	6,000
96507	QLTS26-E400		400	28	38	16	24	6	13	6	12	500	6,000
96508	QLTS26-E425		425	28	38	16	24	6	13	6	12	530	6,000
96509	QLTS26-E450	450	28	38	16	24	6	13	6	12	550	6,000	
96510	QLTS26-E475	475	28	38	16	24	6	13	6	12	570	6,000	
96511	QLTS26-E500	500	28	38	16	24	6	13	6	12	590	6,000	

オーダーNo.	No.	適合Qロックエレメント	A	B	C	D	E	F	G	H	I	質量g	価格
96512	QLTS40-E100	QLTS40	100	32	40	16	26	6	18.5	10	18	300	6,400
96513	QLTS40-E125		125	32	40	16	26	6	18.5	10	18	330	6,400
96514	QLTS40-E150		150	32	40	16	26	6	18.5	10	18	360	6,400
96515	QLTS40-E175		175	32	40	16	26	6	18.5	10	18	400	6,400
96516	QLTS40-E200		200	32	40	16	26	6	18.5	10	18	430	6,400
96517	QLTS40-E225		225	32	40	16	26	6	18.5	10	18	460	6,400
96518	QLTS40-E250		250	32	40	16	26	6	18.5	10	18	500	6,400
96519	QLTS40-E275		275	32	40	16	26	6	18.5	10	18	530	6,400
96520	QLTS40-E300		300	32	40	16	26	6	18.5	10	18	570	6,400
96521	QLTS40-E325		325	32	40	16	26	6	18.5	10	18	600	6,400
96522	QLTS40-E350		350	32	40	16	26	6	18.5	10	18	630	6,700
96523	QLTS40-E375		375	32	40	16	26	6	18.5	10	18	670	6,700
96524	QLTS40-E400		400	32	40	16	26	6	18.5	10	18	700	6,700
96525	QLTS40-E425		425	32	40	16	26	6	18.5	10	18	730	6,700
96526	QLTS40-E450		450	32	40	16	26	6	18.5	10	18	770	6,700
96527	QLTS40-E475		475	32	40	16	26	6	18.5	10	18	800	6,700
96528	QLTS40-E500		500	32	40	16	26	6	18.5	10	18	840	6,700
96529	QLTS40-E525		525	32	40	16	26	6	18.5	10	18	870	6,700
96530	QLTS40-E550	550	32	40	16	26	6	18.5	10	18	900	6,700	
96531	QLTS40-E575	575	32	40	16	26	6	18.5	10	18	940	6,700	
96532	QLTS40-E600	600	32	40	16	26	6	18.5	10	18	970	6,700	