



RoHS対応 サイズ追加

ERON®

No.E-660


SOCKET SCREWS

ソケットスクリュー

材質 SCM435

熱処理 焼入HRC30±5

表面処理 黒染め

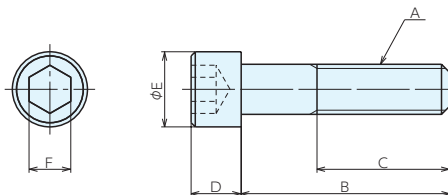

仕様・価格表

1本価格

オーダーNo.	No.	A(並目)	B	C	D	E	F	質量g	価格	
	50885	SKS04010	M 4×0.7	10	10	4	7	3	2	70
	50886	SKS04015	M 4×0.7	15	15	4	7	3	2	70
	50887	SKS04020	M 4×0.7	20	20	4	7	3	2	70
	50888	SKS04025	M 4×0.7	25	25	4	7	3	3	80
	50889	SKS04030	M 4×0.7	30	20	4	7	3	3	95
	50890	SKS04035	M 4×0.7	35	20	4	7	3	3	100
	50891	SKS04040	M 4×0.7	40	20	4	7	3	4	110
ベースエレメント	50892	SKS05010	M 5×0.8	10	10	5	8.5	4	3	70
クランプユニット	50893	SKS05012	M 5×0.8	12	12	5	8.5	4	3	70
	50894	SKS05015	M 5×0.8	15	15	5	8.5	4	3	70
ロケータイングエレメント	50895	SKS05020	M 5×0.8	20	20	5	8.5	4	4	70
	50896	SKS05025	M 5×0.8	25	25	5	8.5	4	4	80
クランプングパーツ	50897	SKS05030	M 5×0.8	30	22	5	8.5	4	5	95
	50898	SKS05035	M 5×0.8	35	22	5	8.5	4	6	100
	50899	SKS05040	M 5×0.8	40	22	5	8.5	4	7	110
補助ベース	38083	SKS06015	M 6×1.0	15	15	6	10	5	5	110
	38084	SKS06020	M 6×1.0	20	20	6	10	5	6	110
マシンバイス	38085	SKS06025	M 6×1.0	25	25	6	10	5	7	110
	38086	SKS06030	M 6×1.0	30	30	6	10	5	8	110
ボール盤バイス	38087	SKS06035	M 6×1.0	35	24	6	10	5	8	160
	38088	SKS06040	M 6×1.0	40	24	6	10	5	9	160
技術資料	38089	SKS06045	M 6×1.0	45	24	6	10	5	9	210
	38090	SKS06050	M 6×1.0	50	24	6	10	5	10	210
索引	38091	SKS08015	M 8×1.25	15	15	8	13	6	8	180
	38092	SKS08020	M 8×1.25	20	20	8	13	6	10	180
	38093	SKS08025	M 8×1.25	25	25	8	13	6	15	180
	38094	SKS08030	M 8×1.25	30	30	8	13	6	15	180
	38095	SKS08035	M 8×1.25	35	35	8	13	6	17	180
	38096	SKS08040	M 8×1.25	40	28	8	13	6	18	180
	38097	SKS08045	M 8×1.25	45	28	8	13	6	20	220
	38098	SKS08050	M 8×1.25	50	28	8	13	6	22	220
	38099	SKS08055	M 8×1.25	55	28	8	13	6	24	220
	38100	SKS08060	M 8×1.25	60	28	8	13	6	25	220
	38101	SKS08065	M 8×1.25	65	28	8	13	6	25	220
	38102	SKS08070	M 8×1.25	70	28	8	13	6	25	220
	38103	SKS08075	M 8×1.25	75	28	8	13	6	27	220
	38104	SKS08080	M 8×1.25	80	28	8	13	6	30	220
	38105	SKS08090	M 8×1.25	90	28	8	13	6	33	250
	38106	SKS08100	M 8×1.25	100	28	8	13	6	43	250