


F6

Flexible Hose with Fluororesin

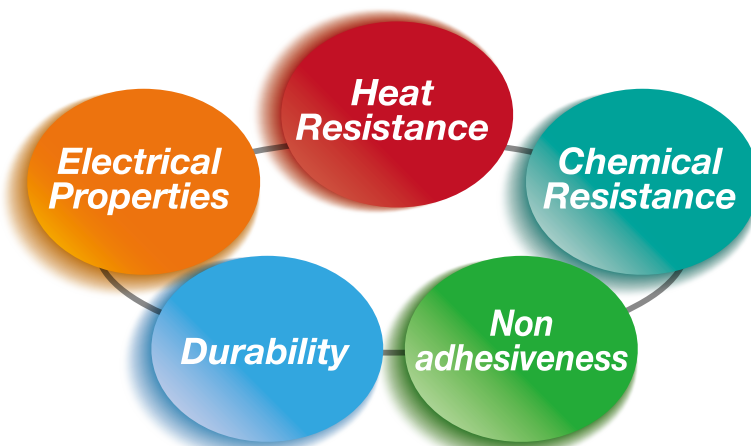

NK-FJ-F Flange Type

DN: 15mm(1/2") ~ 100mm(4") Length: 200mm ~ 3M
 NK-FJP-F/Spiral Tube DN: 32mm(1-1/4") ~

NK-FJIS-S/Inserted Tube
 NK-FNK-FJS-F/Straight Tube DN: 15mm(1/2") ~ 25mm(1")

NK-FJIS-S

① Flexible Tube	Stainless Steel
② Braid	Stainless Steel
③ Collar	Stainless Steel
④ Flange	Stainless Steel
⑤ Back-up Gasket	Non Asbestos
⑥ Inner Tube	PTFE

NK-FJP-F

① Flange	Carbon Steel, Stainless Steel
② FL Fitting	Stainless Steel
③ Tube	PTFE
④ Braid	Stainless Steel
⑤ Back-up Gasket	Non Asbestos



NK-FJS-F

① Flange	Carbon Steel, Stainless Steel
② Stub End	Stainless Steel
③ Tube	PTFE
④ Braid	Stainless Steel
⑤ Guard Spring	Carbon Steel, Stainless Steel
⑥ Ring	Stainless Steel
⑦ Back-up Gasket	Non Asbestos