

DIGITAL CALIPER GAUGE



Wide measuring range of 0-150mm!



USE

- For outside diameter measurement

MATERIAL

- Body : Steel, Plastic

FEATURES

- Digital display for easy reading
- Wide measuring range of 0-150mm

POWER


- One CR2032 (Lithium) battery included for testing

Order No.	Model No.	Resolution (mm)	Measuring Range (mm)	Accuracy* (mm)	Weight
NEW152053	EDC-A1150	0.1	0-150	±0.2	140g

* Quantization Error (± 1 digit) not included

DIMENSIONS

Units : mm

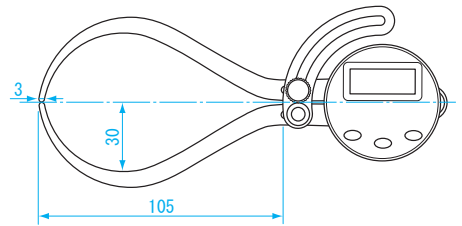

DIAL CALIPER GAUGES (OUTSIDE)



DIAL GAUGES

DIAL GAUGES

DIAL INDICATORS

THICKNESS GAUGES


BORE GAUGES

CALIPER GAUGES


HARDNESS-TENSION GAUGE

MAGNETIC BASE


AO TYPE

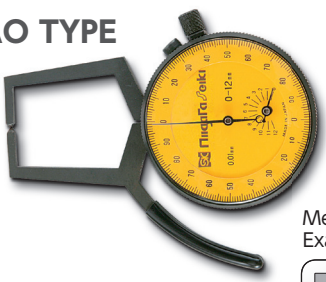


AO-1

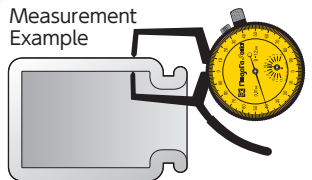

BO TYPE

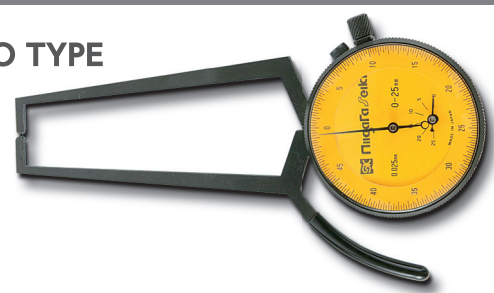


BO-1

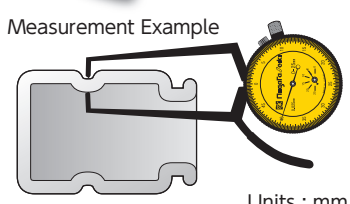

DIMENSIONS

Units : mm

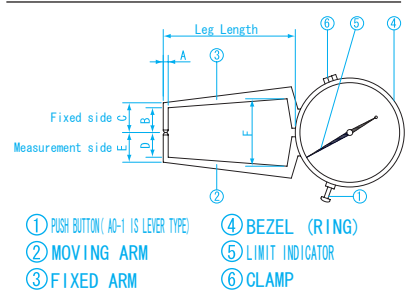

USE

- Measuring wall thickness and irregular parts

MATERIAL

- Body : Steel

Model No.	Leg Length	A	B	C	D	E	F
AO-1	40	2.3	11.5	14.5	11.5	14.5	27
AO-2	40	2.3	18.5	20.5	11.5	14.5	45
AO-3	40	2.3	8.5	10.5	11.5	14.5	49
BO-1	80	2.3	8.5	10.5	8.5	10.5	27.5
BO-2	80	2.3	8.5	10.5	8.5	10.5	46.5
BO-3	80	2.3	8.5	10.5	8.5	10.5	55.5

* Custom shape product available by special order

* Gauge head : φ 1.6mm ball

Order No.	Model No.	Graduation (mm)	Measuring Range (mm)	Accuracy (mm)
151561	AO-1	0.01	0~12	±0.05
151562	AO-2	0.01	10~22	±0.05
151563	AO-3	0.01	20~32	±0.05
151571	BO-1	0.025	0~25	±0.05
151572	BO-2	0.025	10~35	±0.05
151573	BO-3	0.025	20~45	±0.05