



LEVEL METER LM-90

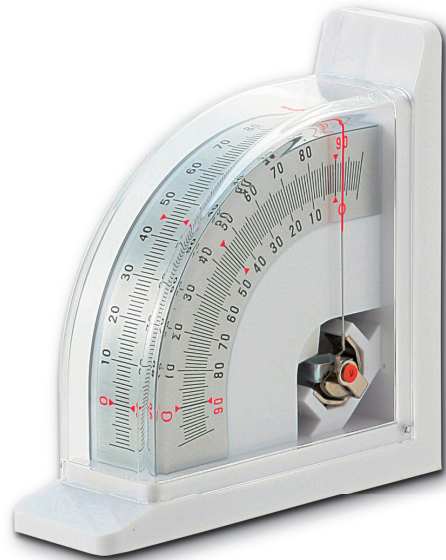

ANGLE

Analog type goniometer with magnetic base

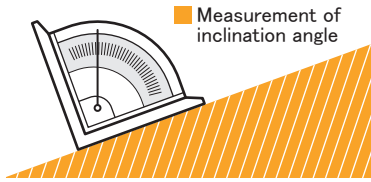

USE • Measurement of inclination angle

MATERIALS

- Plastic

FEATURES

- Analog dial easier to read than bubble tube type meter
- With magnetic base to enables measuring horizontal and vertical angle
- Light weight, easy to use

SPECIFICATIONS

- Measuring range : 0 ~ 90 °
- Graduation : 1 °
- Accuracy : ± 0.5 °



Order No.	Model No.	Dimensions (H) × (W) × (T) (mm)	Weight
011010	LM-90	95 × 95 × 30	120g

07

LEVEL MATE LM-360



Analog type goniometer With magnet for vertical surfaces

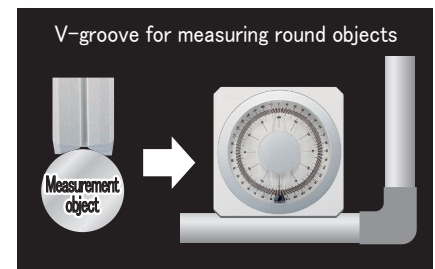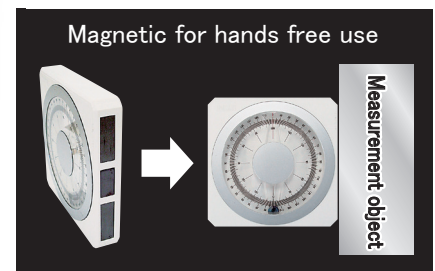

USE

- Angle of tilt measurement
- Mechanical assembly, installation
- Setting angles for machine work
- Miscellaneous plumbing work
- Construction and related work

MATERIALS

- Plastic

FEATURES

- V groove on bottom, magnet for vertical surface

SPECIFICATIONS

- Measurement range : 0 ~ 360 °
- Graduation : 1 °
- Reading accuracy : ± 0.5 °

Order No.	Model No.	Dimensions (H) × (W) × (T) (mm)	Weight
011030	LM-360	110 × 110 × 20	140g

ANGLE

LEVELNIC

PRECISION LEVEL

ANGLE LEVEL

LEVEL

PROTRACTOR