


ELECTROPLATED DIAMOND/CBN BURS

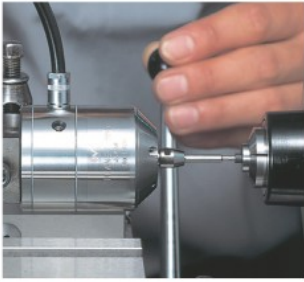

3.0 mm shank diameter series.
Extremely durable for high precision and fine finish internal grinding.

SHANK ϕ 3.0

1 pc./pack

60,000 min⁻¹

	ϕ 0.5	ϕ 0.6	ϕ 0.7	ϕ 0.8	ϕ 0.9	ϕ 1.0	
Diamond	#200	11803	11804	11805	11806	11807	11808
	#325	11803	11804	11805	11806	11807	11808
	#600	11813	11814	11815	11816	11817	11818
CBN	#200	11823	11824	11825	11826	11827	11828
	#325	11823	11824	11825	11826	11827	11828
	#600	11833	11834	11835	11836	11837	11838

1 pc./pack

60,000 min⁻¹

	ϕ 0.5	ϕ 0.6	ϕ 0.7	ϕ 0.8	ϕ 0.9	ϕ 1.0	
Diamond	#200	11793	11794	11795	11796	11797	11798
	#325	11853	11854	11855	11856	11857	11858
	#600	11863	11864	11865	11866	11867	11868
CBN	#200	11794	11795	11796	11797	11798	11799
	#325	11873	11874	11875	11876	11877	11878
	#600	11883	11884	11885	11886	11887	11888

SHANK ϕ 3.0

1 pc./pack

	ϕ 0.1	ϕ 0.2	ϕ 0.3	ϕ 0.4	ϕ 0.5	
Diamond	#1,000	12001	12002	12003	12004	12005
	#600	12001	12002	12003	12004	12005
	#320	12001	12002	12003	12004	12005
CBN	#1,000	12011	12012	12013	12014	12015
	#600	12011	12012	12013	12014	12015
	#320	12011	12012	12013	12014	12015

* Carbide shank is used for ϕ 0.1 and ϕ 0.2 mm.

1 pc./pack

80,000 min⁻¹

	ϕ 0.5	ϕ 0.6	ϕ 0.7	ϕ 0.8	ϕ 0.9	
Diamond	#320	12006	12007	12008	12009	12010
	#270	12016	12017	12018	12019	12020
	#230	12006	12007	12008	12009	12010
CBN	#320	12016	12017	12018	12019	12020
	#270	12016	12017	12018	12019	12020
	#230	12016	12017	12018	12019	12020

SHANK ϕ 3.0

1 pc./pack

80,000 min⁻¹

	ϕ 1	ϕ 1.2	ϕ 1.5	ϕ 1.7	ϕ 2	ϕ 2.2	ϕ 2.5	ϕ 3	
Diamond	#100	12051	12052	12053	12054	12055	12056	12057	12058
	#140	12051	12052	12053	12054	12055	12056	12057	12058
	#220	12091	12092	12093	12094	12095	12096	12097	12098
	#320	12111	12112	12113	12114	12115	12116	12117	12118
	#600	12131	12132	12133	12134	12135	12136	12137	12138
	#220	12091	12092	12093	12094	12095	12096	12097	12098
CBN	#120	12151	12152	12153	12154	12155	12156	12157	12158
	#140	12151	12152	12153	12154	12155	12156	12157	12158
	#220	12171	12172	12173	12174	12175	12176	12177	12178
	#220	12171	12172	12173	12174	12175	12176	12177	12178

1 pc./pack

80,000 min⁻¹ 70,000 min⁻¹

	ϕ 3.2	ϕ 3.5	ϕ 4	ϕ 4.5	ϕ 5	ϕ 5.5	ϕ 6	
Diamond	#100	12059	12060	12061	12062	12063	12064	12065
	#140	12039	12040	12041	12042	12043	12044	12045
	#220	12099	12100	12101	12102	12103	12104	12105
	#320	12119	12120	12121	12122	12123	12124	12125
	#600	12139	12140	12141	12143	12145		
CBN	#120	12159	12160	12161	12162	12163	12164	12165
	#220	12179	12180	12181	12182	12183	12184	12185

* Order in standard package quantities.

Diamond / CBN

Carbide Cutters

Specialty Tools

Mounted Points

Rubberized Abrasives

Flap Wheels

Polishing Brushes

Felt Bobs

Abrasive Compounds & Polishing Tools

NSK Exclusive Tools