

RUBBERIZED ABRASIVES




1.6 mm shank diameter series. Short type for high-speed rotation. Ideal for grinding very small parts.



2.34 mm shank diameter series. Perfect for precision finishing and deburring.


SHANK Ø1.6

10 pcs./pack WA Silicon Polisher

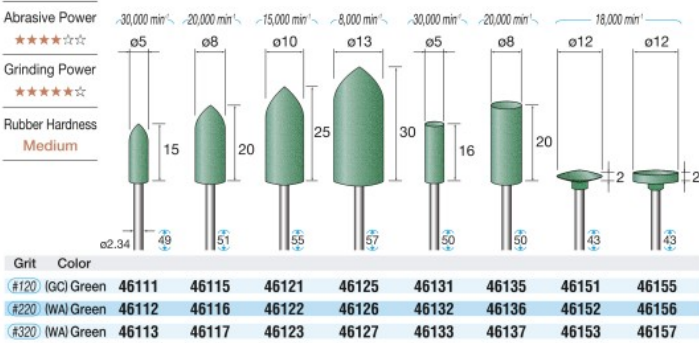


SHANK Ø2.34

10 pcs./pack WA GC Green Polisher

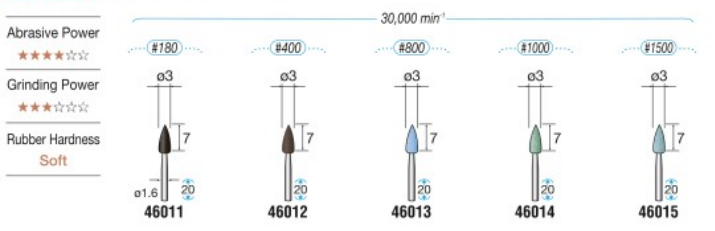


10 pcs./pack WA High Shine Polisher

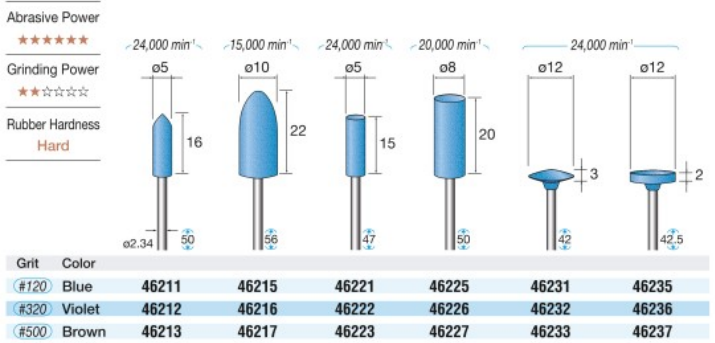

SHANK Ø2.34

10 pcs./pack WA Silicon Polisher

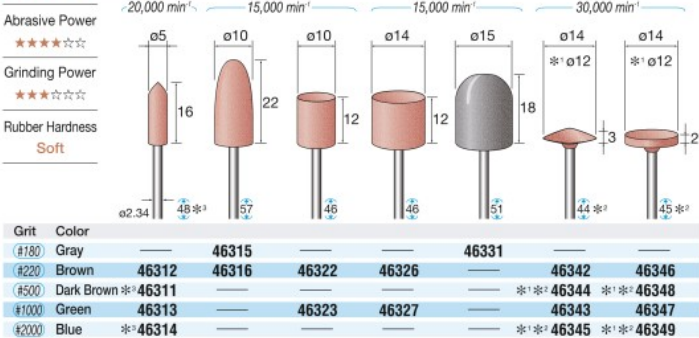


*1 46344,46345,46348,46349 is diameter ø12.
*2 46344,46345,46348,46349 is Total Length 42mm.
*3 46311,46314 is Total Length 50mm.



3.0 mm shank diameter series. Produces a smoother, better surface finish due to greater pliability versus standard grindstones.

SHANK Ø3.0

10 pcs./pack WA Power Polisher

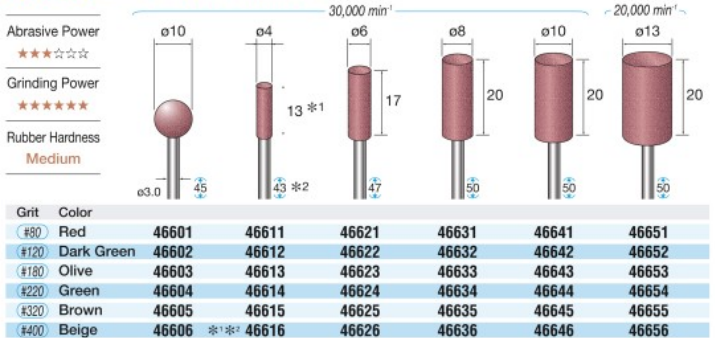

*1 46616 is Total Length 15mm. *2 46616 is Total Length 45mm.