


E4000 Controller / Motor cord

E4000 CONTROLLER

Code No. **8472**

Controller

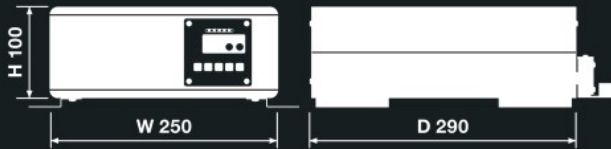

External Input / Output Control Signal Operation

- External Input
Motor Rotating / Stopped, Error Released, Rotating Direction, Motor Speed Setting and etc.
 - External Monitor
Motor Current, Error, Warning, Rotating pulse and etc.
 - Parameter Setting
Maximum motor speed setting, Fix the motor speed
- ※ For more information, please refer to the operation manual on our website.



Max. power	Input Voltage	Speed Range	Power consumption	Air consumption	Weight
1,200w	AC200~240v Without plug Multiple output power	1,000~40,000min ⁻¹	3.2A	100Nℓ/min (0.2~0.35MPa)	6.7kg

Standard Accessories	Power cord : 4m / Air hose with filter(K-251:2058) : 2M / Motor connector cap(provided)
	Connector cover(provided) / Bracket : 4pcs. / Rubber pad : 4pcs.

	Motor cord	Code No.	Model	Length	Standard Accessories	Compatible model
Power cable with Air hose	2M	9253	EMCD-4000-2M	2m	Air hose	BMS-4020-BMS-4040-BMS-4020RA BMS-4040RA-BMS-4020 2M BMS-4040 2M-EM-4020-EM-4040 EM-4020A-EM-4040A BMS-4020-MQL-BMS-4020-MQL-2M BMS-4040-MQL-BMS-4040-MQL-2M BMS-4020-MQL-CHK-BMS-4020-MQL-CHK-2M BMS-4040-MQL-CHK-BMS-4040-MQL-CHK-2M BMS-4040-RGD-03M-BMS-4040-RGD-2M BMS-4040RA-RGD-03M-BMS-4040RA-RGD-2M
	4M	9254	EMCD-4000-4M	4m		
	6M	9255	EMCD-4000-6M	6m		
	8M	9256	EMCD-4000-8M	8m		
	Connector Diameter : ø30mm					
Signal cable	2M	9257	EMCD-4000S-2M	2m	-	BMS-4020-BMS-4040-BMS-4020RA BMS-4040RA-BMS-4020 2M BMS-4040 2M-EM-4020-EM-4040 EM-4020A-EM-4040A BMS-4020-MQL-BMS-4020-MQL-2M BMS-4040-MQL-BMS-4040-MQL-2M BMS-4020-MQL-CHK-BMS-4020-MQL-CHK-2M BMS-4040-MQL-CHK-BMS-4040-MQL-CHK-2M BMS-4040-RGD-03M-BMS-4040-RGD-2M BMS-4040RA-RGD-03M-BMS-4040RA-RGD-2M
	4M	9258	EMCD-4000S-4M	4m		
	6M	9259	EMCD-4000S-6M	6m		
	8M	9260	EMCD-4000S-8M	8m		
	Connector Diameter : ø16mm					

※ Power cable and Signal cable should be used as set.
 ※ 8M motor cord cannot be used for angle cord type / 2M type.

Operation panel extension cord	Code No.	Model	Specifications	Compatible model
	8474	E4000-PEX4	Cord length : 4m Screw (M3) : 4pcs.	E4000 Controller