



90°エルボ

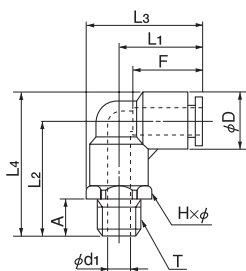

Mねじ

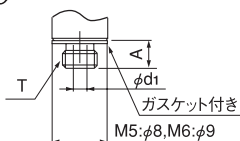


●ミリサイズ

| 品番 | 適用チューブ外径 (mm) | Tねじサイズ (M,R) | L1 (mm) | L2 (mm) | L3 (mm) | L4 (mm) | A (mm) | Fチューブ挿入長さ (mm) | H×φ二面幅 (mm) | D (mm) | d1 (mm) | 最小内径 (mm) | 有効断面積 (mm ²) | 質量 (g) |
|-----------|---------------|--------------|---------|---------|---------|---------|--------|----------------|-------------|--------|---------|-----------|--------------------------|--------|
| AL4-M5 | 4 | M5×0.8 | 17.2 | 20.2 | 22.7 | 25.1 | 4.0 | 13 | 10.0×11.0 | 9.8 | 2.0 | 2.0 | 3.0 | 7.0 |
| AL4-R1/8 | 4 | R1/8 | 17.2 | 22.7 | 22.7 | 27.6 | 8.0 | 13 | 10.0×11.0 | 9.8 | 5.0 | 3.0 | 4.0 | 9.0 |
| AL4-R1/4 | 4 | R1/4 | 17.2 | 26.7 | 24.9 | 31.6 | 11.0 | 13 | 14.0×15.4 | 9.8 | 7.0 | 3.0 | 4.0 | 16.0 |
| AL6-M5 | 6 | M5×0.8 | 18.5 | 22.7 | 25.0 | 29.0 | 4.0 | 15 | 12.0×13.0 | 12.6 | 2.0 | 2.0 | 3.5 | 10.0 |
| AL6-M6 | 6 | M6×1.0 | 18.5 | 22.7 | 25.0 | 29.0 | 5.0 | 15 | 12.0×13.0 | 12.6 | 3.0 | 3.0 | 4.5 | 11.0 |
| AL6-R1/8 | 6 | R1/8 | 18.5 | 25.2 | 25.0 | 31.5 | 8.0 | 15 | 12.0×13.0 | 12.6 | 5.0 | 5.0 | 12.0 | 18.0 |
| AL6-R1/4 | 6 | R1/4 | 18.5 | 29.2 | 26.2 | 35.5 | 11.0 | 15 | 14.0×15.4 | 12.6 | 7.0 | 5.0 | 12.0 | 18.0 |
| AL6-R3/8 | 6 | R3/8 | 18.5 | 30.2 | 27.8 | 36.5 | 12.0 | 15 | 17.0×18.5 | 12.6 | 9.0 | 5.0 | 12.0 | 26.0 |
| AL8-R1/8 | 8 | R1/8 | 20.7 | 26.2 | 28.4 | 33.5 | 8.0 | 16 | 14.0×15.4 | 14.5 | 5.0 | 5.0 | 18.5 | 15.0 |
| AL8-R1/4 | 8 | R1/4 | 20.7 | 30.2 | 28.4 | 37.5 | 11.0 | 16 | 14.0×15.4 | 14.5 | 7.0 | 7.0 | 23.0 | 20.0 |
| AL8-R3/8 | 8 | R3/8 | 20.7 | 31.2 | 30.0 | 38.5 | 12.0 | 16 | 17.0×18.5 | 14.5 | 9.0 | 7.0 | 23.0 | 28.0 |
| AL10-R1/8 | 10 | R1/8 | 24.7 | 29.2 | 33.9 | 38.0 | 8.0 | 19 | 17.0×18.5 | 17.5 | 5.0 | 5.0 | 22.0 | 22.0 |
| AL10-R1/4 | 10 | R1/4 | 24.7 | 33.2 | 33.9 | 42.0 | 11.0 | 19 | 17.0×18.5 | 17.5 | 7.0 | 7.0 | 34.5 | 27.0 |
| AL10-R3/8 | 10 | R3/8 | 24.7 | 34.2 | 33.9 | 43.0 | 12.0 | 19 | 17.0×18.5 | 17.5 | 9.0 | 9.0 | 37.0 | 33.0 |
| AL10-R1/2 | 10 | R1/2 | 24.7 | 38.2 | 36.9 | 47.0 | 15.0 | 19 | 22.0×24.5 | 17.5 | 12.0 | 9.0 | 37.0 | 52.0 |
| AL12-R1/4 | 12 | R1/4 | 26.3 | 35.7 | 36.8 | 45.7 | 11.0 | 20 | 19.0×21.0 | 20.0 | 7.0 | 7.0 | 36.0 | 34.0 |
| AL12-R3/8 | 12 | R3/8 | 26.3 | 36.7 | 36.8 | 46.7 | 12.0 | 20 | 19.0×21.0 | 20.0 | 9.0 | 9.0 | 43.0 | 39.0 |
| AL12-R1/2 | 12 | R1/2 | 26.3 | 40.7 | 38.6 | 50.7 | 15.0 | 20 | 22.0×24.5 | 20.0 | 12.0 | 10.0 | 43.0 | 56.0 |
| AL16-R3/8 | 16 | R3/8 | 34.9 | 45.0 | 48.4 | 58.8 | 12.0 | 27 | 24.0×27.0 | 28.0 | 11.0 | 11.0 | 70.0 | 70.0 |
| AL16-R1/2 | 16 | R1/2 | 34.9 | 48.0 | 48.4 | 61.8 | 15.0 | 27 | 24.0×27.0 | 28.0 | 12.0 | 12.0 | 93.0 | 84.0 |

※受注生産品

90°メスエルボ

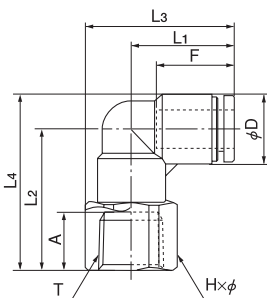

●ミリサイズ

| 品番 | 適用チューブ外径 (mm) | Tねじサイズ (Rc) | L1 (mm) | L2 (mm) | L3 (mm) | L4 (mm) | A (mm) | Fチューブ挿入長さ (mm) | H×φ二面幅 (mm) | D (mm) | 最小内径 (mm) | 有効断面積 (mm ²) | 質量 (g) |
|------------|---------------|-------------|---------|---------|---------|---------|--------|----------------|-------------|--------|-----------|--------------------------|--------|
| AFL4-R1/8 | 4 | Rc1/8 | 17.2 | 21.7 | 24.9 | 22.1 | 8.0 | 13 | 14.0×15.4 | 9.8 | 3.0 | — | — |
| AFL6-R1/8 | 6 | Rc1/8 | 18.5 | 24.2 | 26.2 | 30.5 | 8.0 | 15 | 14.0×15.4 | 12.6 | 5.0 | — | 15.0 |
| AFL6-R1/4 | 6 | Rc1/4 | 18.5 | 28.2 | 27.8 | 34.5 | 12.0 | 15 | 17.0×18.5 | 12.6 | 5.0 | — | 23.0 |
| AFL6-R3/8 | 6 | Rc3/8 | 18.5 | 28.7 | 30.8 | 35.0 | 12.5 | 15 | 22.0×24.5 | 12.6 | 5.0 | — | 37.0 |
| AFL8-R1/8 | 8 | Rc1/8 | 20.7 | 25.2 | 28.4 | 32.5 | 8.0 | 16 | 14.0×15.4 | 14.6 | 7.0 | — | 17.0 |
| AFL8-R1/4 | 8 | Rc1/4 | 20.7 | 29.2 | 30.0 | 36.5 | 12.0 | 16 | 17.0×18.5 | 14.6 | 7.0 | — | 25.0 |
| AFL8-R3/8 | 8 | Rc3/8 | 20.7 | 29.7 | 33.0 | 37.0 | 12.5 | 16 | 22.0×24.5 | 14.6 | 7.0 | — | 38.0 |
| AFL10-R1/4 | 10 | Rc1/4 | 24.7 | 32.2 | 34.0 | 41.0 | 12.0 | 19 | 17.0×18.5 | 17.5 | 9.0 | — | 29.0 |
| AFL10-R3/8 | 10 | Rc3/8 | 24.7 | 33.7 | 37.0 | 42.5 | 12.5 | 19 | 22.0×24.5 | 17.5 | 9.0 | — | 45.0 |
| AFL12-R3/8 | 12 | Rc3/8 | 26.3 | 36.2 | 38.6 | 46.2 | 12.5 | 20 | 22.0×24.5 | 20.0 | 10.0 | — | 49.0 |
| AFL12-R1/2 | 12 | Rc1/2 | 26.3 | 39.2 | 39.6 | 49.2 | 15.5 | 20 | 24.0×26.5 | 20.0 | 10.0 | — | 54.0 |

チューブ

クリップ
チューブ

加工チューブ

プッシュワン
継手

クイックシール
継手

クリップ継手
ケミフイット

竹のこ継手

制御切替・着脱
シリーズ

治具・工具
付属品

技術資料

参考資料