


メスコネクタ

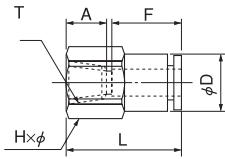

●ミリサイズ


品番	適用チューブ外径 (mm)	Tねじサイズ (Rc)	L (mm)	A (mm)	Fチューブ挿入長さ (mm)	H×φ二面幅 (mm)	D (mm)	最小内径 (mm)	有効断面積 (mm ²)	質量 (g)
EFC4-PT1/8	4	Rc1/8	23.9	8.7	13	14.0×15.4	10.0	3.0	4.0	16.0
EFC6-PT1/8	6	Rc1/8	24.8	8.7	15	14.0×15.4	12.0	5.0	10.5	17.0
EFC6-PT1/4	6	Rc1/4	29.3	13.0	15	17.0×18.5	12.0	5.0	10.5	26.0
EFC8-PT1/4	8	Rc1/4	30.9	13.0	16	17.0×18.5	13.9	7.0	25.0	28.0
EFC8-PT3/8	8	Rc3/8	31.4	13.5	16	22.0×24.5	13.9	7.0	26.0	45.0
EFC10-PT1/4	10	Rc1/4	33.9	13.0	19	17.0×18.5	16.9	9.0	40.0	34.0
EFC10-PT3/8	10	Rc3/8	34.4	13.5	19	22.0×24.5	16.9	9.0	40.0	50.0
EFC10-PT1/2	10	Rc1/2	38.4	17.5	19	24.0×26.5	16.9	9.0	40.0	56.0
EFC12-PT1/4	12	Rc1/4	34.5	13.0	20	19.0×21.0	19.0	10.0	45.0	43.0
EFC12-PT3/8	12	Rc3/8	35.3	13.5	20	22.0×24.5	19.0	11.0	50.0	50.0
EFC12-PT1/2	12	Rc1/2	39.3	17.5	20	24.0×26.5	19.0	11.0	50.0	58.0

●インチサイズ


品番	適用チューブ外径 (inch)	Tねじサイズ (Rc)	L (mm)	A (mm)	Fチューブ挿入長さ (mm)	H×φ二面幅 (mm)	D (mm)	最小内径 (mm)	有効断面積 (mm ²)	質量 (g)
EFC1/4-PT1/8	1/4	Rc1/8	25.0	8.7	15	14.0×15.4	12.0	5.0	12.0	17.0
EFC1/4-PT1/4	1/4	Rc1/4	29.5	13.0	15	17.0×18.5	12.0	5.0	12.0	26.0
EFC5/16-PT1/4	5/16	Rc1/4	30.6	13.0	16	17.0×18.5	13.9	7.0	25.0	28.0
EFC5/16-PT3/8	5/16	Rc3/8	31.1	13.5	16	22.0×24.5	13.9	7.0	26.0	45.0
EFC3/8-PT1/4	3/8	Rc1/4	33.5	13.0	19	17.0×18.5	16.9	9.0	35.0	34.0
EFC3/8-PT3/8	3/8	Rc3/8	34.0	13.5	19	22.0×24.5	16.9	9.0	35.0	50.0
EFC3/8-PT1/2	3/8	Rc1/2	38.4	17.5	19	24.0×26.5	16.9	9.0	35.0	56.0
EFC1/2-PT1/4	1/2	Rc1/4	35.3	13.0	21	22.0×24.5	20.0	10.0	48.0	43.0
EFC1/2-PT3/8	1/2	Rc3/8	35.3	13.5	21	22.0×24.5	20.0	11.0	66.5	50.0
EFC1/2-PT1/2	1/2	Rc1/2	39.3	17.5	21	24.0×26.5	20.0	11.0	66.5	58.0

☞ インチサイズにはめっき処理をしています。

90°エルボ

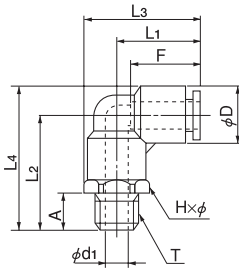

Mねじ

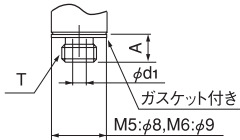

●ミリサイズ

品番	適用チューブ外径 (mm)	Tねじサイズ (M,R)	L1 (mm)	L2 (mm)	L3 (mm)	L4 (mm)	A (mm)	Fチューブ挿入長さ (mm)	H×φ二面幅 (mm)	D (mm)	d1 (mm)	最小内径 (mm)	有効断面積 (mm ²)	質量 (g)
EL4-M5	4	M5×0.8	17.2	20.2	22.7	25.1	4.0	13	10.0×11.0	9.8	2.0	2.0	3.0	7.0
EL4-PT1/8	4	R1/8	17.2	22.7	22.7	27.6	8.0	13	10.0×11.0	9.8	5.0	3.0	4.0	9.0
EL4-PT1/4	4	R1/4	17.2	26.7	24.9	31.6	11.0	13	14.0×15.4	9.8	7.0	3.0	4.0	16.0
EL6-M5	6	M5×0.8	18.5	22.7	25.0	29.0	4.0	15	12.0×13.0	12.6	2.0	2.0	3.5	10.0
EL6-M6	6	M6×1.0	18.5	22.7	25.0	29.0	5.0	15	12.0×13.0	12.6	3.0	3.0	4.5	11.0
EL6-PT1/8	6	R1/8	18.5	25.2	25.0	31.5	8.0	15	12.0×13.0	12.6	5.0	5.0	12.0	18.0
EL6-PT1/4	6	R1/4	18.5	29.2	26.2	35.5	11.0	15	14.0×15.4	12.6	7.0	5.0	12.0	18.0
EL6-PT3/8	6	R3/8	18.5	30.2	27.8	36.5	12.0	15	17.0×18.5	12.6	9.0	5.0	12.0	26.0
EL8-PT1/8	8	R1/8	20.7	26.2	28.4	33.5	8.0	16	14.0×15.4	14.5	5.0	5.0	18.5	15.0
EL8-PT1/4	8	R1/4	20.7	30.2	28.4	37.5	11.0	16	14.0×15.4	14.5	7.0	7.0	23.0	20.0
EL8-PT3/8	8	R3/8	20.7	31.2	30.0	38.5	12.0	16	17.0×18.5	14.5	9.0	7.0	23.0	28.0
EL10-PT1/8	10	R1/8	24.7	29.2	33.9	38.0	8.0	19	17.0×18.5	17.5	5.0	5.0	22.0	22.0
EL10-PT1/4	10	R1/4	24.7	33.2	33.9	42.0	11.0	19	17.0×18.5	17.5	7.0	7.0	34.5	27.0
EL10-PT3/8	10	R3/8	24.7	34.2	33.9	43.0	12.0	19	17.0×18.5	17.5	9.0	9.0	37.0	33.0
EL10-PT1/2	10	R1/2	24.7	38.2	36.9	47.0	15.0	19	22.0×24.5	17.5	12.0	9.0	37.0	52.0
EL12-PT1/4	12	R1/4	26.3	35.7	36.8	45.7	11.0	20	19.0×21.0	20.0	7.0	7.0	36.0	34.0
EL12-PT3/8	12	R3/8	26.3	36.7	36.8	46.7	12.0	20	19.0×21.0	20.0	9.0	9.0	43.0	39.0
EL12-PT1/2	12	R1/2	26.3	40.7	38.6	50.7	15.0	20	22.0×24.5	20.0	12.0	10.0	43.0	56.0
EL16-PT3/8	16	R3/8	34.9	45.0	48.4	58.8	12.0	27	24.0×27.0	28.0	11.0	11.0	70.0	70.0
EL16-PT1/2	16	R1/2	34.9	48.0	48.4	61.8	15.0	27	24.0×27.0	28.0	12.0	12.0	93.0	84.0

※受注生産品

●インチサイズ

品番	適用チューブ外径 (inch)	Tねじサイズ (M,R)	L1 (mm)	L2 (mm)	L3 (mm)	L4 (mm)	A (mm)	Fチューブ挿入長さ (mm)	H×φ二面幅 (mm)	D (mm)	d1 (mm)	最小内径 (mm)	有効断面積 (mm ²)	質量 (g)
EL1/4-M5	1/4	M5×0.8	18.1	22.7	24.6	29.0	4.0	15	12.0×13.0	13.0	2.0	2.0	3.0	10.0
EL1/4-PT1/8	1/4	R1/8	18.1	25.2	24.6	31.5	8.0	15	12.0×13.0	13.0	5.0	5.0	13.0	18.0
EL1/4-PT1/4	1/4	R1/4	18.1	29.2	25.8	35.5	11.0	15	14.0×15.4	13.0	7.0	5.0	13.0	18.0
EL1/4-PT3/8	1/4	R3/8	18.1	30.2	27.4	36.5	12.0	15	17.0×18.5	13.0	9.0	5.0	13.0	26.0
EL5/16-PT1/8	5/16	R1/8	20.6	26.2	28.3	33.5	8.0	16	14.0×15.4	15.0	5.0	5.0	18.5	15.0
EL5/16-PT1/4	5/16	R1/4	20.6	30.2	28.3	37.5	11.0	16	14.0×15.4	15.0	7.0	7.0	23.0	20.0
EL5/16-PT3/8	5/16	R3/8	20.6	31.2	29.9	38.5	12.0	16	17.0×18.5	15.0	9.0	7.0	23.0	28.0
EL3/8-PT1/8	3/8	R1/8	24.4	29.2	33.7	38.0	8.0	19	17.0×18.5	18.0	5.0	5.0	19.0	22.0
EL3/8-PT1/4	3/8	R1/4	24.4	33.2	33.7	42.0	11.0	19	17.0×18.5	18.0	7.0	7.0	30.0	27.0
EL3/8-PT3/8	3/8	R3/8	24.4	34.2	33.7	43.0	12.0	19	17.0×18.5	18.0	9.0	9.0	32.0	33.0
EL3/8-PT1/2	3/8	R1/2	24.4	38.2	36.7	47.0	15.0	19	22.0×24.5	18.0	12.0	9.0	32.0	52.0
EL1/2-PT1/4	1/2	R1/4	26.5	35.7	37.0	46.2	11.0	21	19.0×21.0	21.5	7.0	7.0	37.0	34.0
EL1/2-PT3/8	1/2	R3/8	26.5	36.7	37.0	47.2	12.0	21	19.0×21.0	21.5	9.0	9.0	53.0	39.0
EL1/2-PT1/2	1/2	R1/2	26.5	40.7	38.7	51.2	15.0	21	22.0×24.5	21.5	12.0	10.0	55.5	56.0

☞ インチサイズにはめっき処理をしています。

チューブ

クリップ

加工チューブ

プッシュワン継手

クイックシール継手

クリップ継手ケミフィット

竹のこ継手

制御切替着脱シリーズ

治具・工具・付属品

技術資料

参考資料