


Q.D.C. 101シリーズ

ニップル

プッシュワン®タイプ

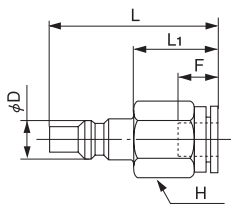


品番	適用 チューブ サイズ (mm)	L (mm)	L ₁ (mm)	F チューブ 挿入長さ (mm)	H 二面幅 (mm)	D (mm)	質量 (g)
101N4-6E	6	33.0	16.5	15	12.0	8.3	13.0
101N4-8E	8	34.5	18.0	16	14.0	8.3	16.0
101N4-10E	10	38.0	21.5	17	17.0	8.3	27.0

メスねじタイプ

黄銅製



ステンレス製

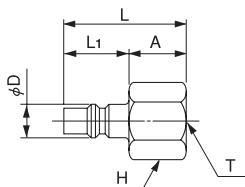

品番	T ねじ サイズ (Rc)	L (mm)	L ₁ (mm)	A (mm)	H 二面幅 (mm)	D (mm)	質量 (g)
101N4-2F	Rc1/8	29.5	16.6	12.9	14.0	8.3	16.5
101N4-4F	Rc1/4	32.8	16.6	16.2	14.0	8.3	25.0
※ S101N4-2F	Rc1/8	29.5	16.6	12.9	14.0	8.3	16.5
※ S101N4-4F	Rc1/4	32.8	16.6	16.2	14.0	8.3	25.0


※受注生産品

オスねじタイプ

黄銅製




ステンレス製

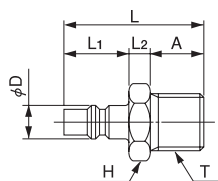


品番	T ねじ サイズ (R)	L (mm)	L ₁ (mm)	L ₂ (mm)	A (mm)	H 二面幅 (mm)	D (mm)	質量 (g)
101N4-2M	R1/8	31.4	16.6	4.8	10.0	14.0	8.3	13.5
101N4-4M	R1/4	35.4	16.6	4.8	14.0	14.0	8.3	18.0
※ S101N4-2M	R1/8	31.4	16.6	4.8	10.0	14.0	8.3	13.5
※ S101N4-4M	R1/4	35.4	16.6	4.8	14.0	14.0	8.3	18.0

※受注生産品

N2-1-1/4専用タイプ

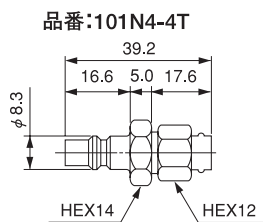

ナイロンコイルチューブ S1/4専用タイプ

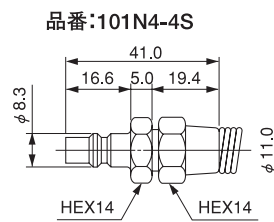

φ8ホース用タイプ

