




適用する内径、外径、長さから Parts No. を選んでください。


(例)内径5mm、外径10mm、長さ4mmの場合

GSF - 051004


Parts No. でご指示ください。

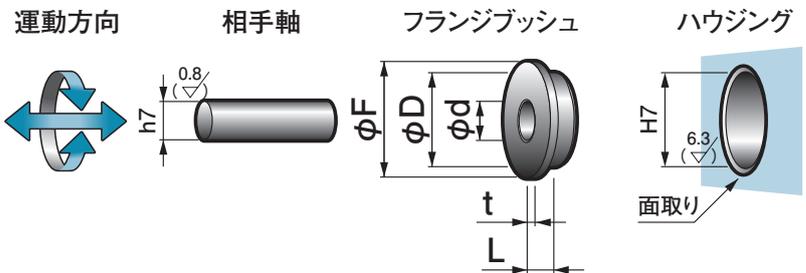

タイプ A

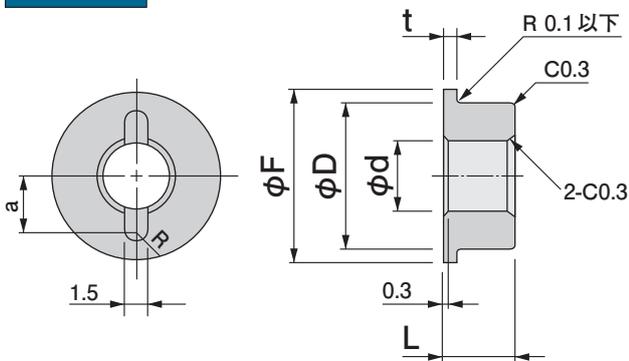

タイプ B

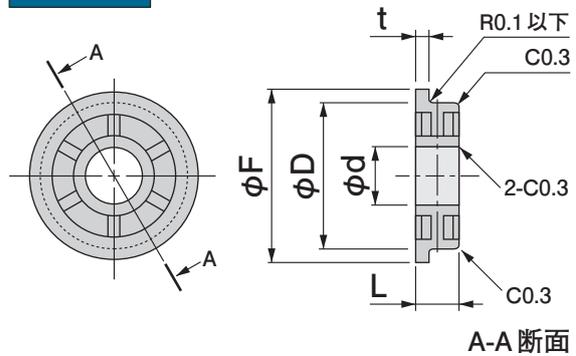

| Parts No. | 内径 | | 外径 | | 長さ | | フランジ | | | a | 許容回転数 S ⁻¹ [rpm] | 許容荷重 N [kgf] | タイプ | ベアリング 呼番号 |
|-------------------|----|----------------|----|------------|-----|-----------|------|-----|-----------|-----|--------------------------------|-----------------|-----|--------------|
| | φd | 公差 | φD | 公差 | L | 公差 | φF | t | 公差 | | | | | |
| GSF-040803 | 4 | +0.09 +0.04 | 8 | +0.05 0 | 3 | 0 -0.1 | 9.2 | 0.6 | 0 -0.1 | 2.8 | 53.33 {3,200} | 12 {1.2} | A | — |
| GSF-040904 | 4 | +0.09 +0.04 | 9 | +0.05 0 | 4 | 0 -0.1 | 10.3 | 1.0 | 0 -0.1 | 3.0 | 53.33 {3,200} | 16 {1.6} | A | 684 |
| GSF-041104 | 4 | +0.09 +0.04 | 11 | +0.05 0 | 4 | 0 -0.1 | 12.5 | 1.0 | 0 -0.1 | — | 53.33 {3,200} | 16 {1.6} | A | 694 |
| GSF-041204 | 4 | +0.09 +0.04 | 12 | +0.05 0 | 4 | 0 -0.1 | 13.5 | 1.0 | 0 -0.1 | — | 53.33 {3,200} | 16 {1.6} | B | 604 |
| GSF-051004 | 5 | +0.09 +0.04 | 10 | +0.05 0 | 4 | 0 -0.1 | 11.6 | 0.8 | 0 -0.1 | 3.5 | 41.67 {2,500} | 20 {2.0} | A | — |
| GSF-051105 | 5 | +0.09 +0.04 | 11 | +0.05 0 | 5 | 0 -0.1 | 12.5 | 1.0 | 0 -0.1 | 4.0 | 41.67 {2,500} | 25 {2.6} | A | 685 |
| GSF-051304 | 5 | +0.09 +0.04 | 13 | +0.05 0 | 4 | 0 -0.1 | 15.0 | 1.0 | 0 -0.1 | — | 41.67 {2,500} | 20 {2.0} | B | 695 |
| GSF-061003 | 6 | +0.09 +0.04 | 10 | +0.05 0 | 3 | 0 -0.1 | 11.2 | 0.6 | 0 -0.1 | 3.8 | 35.00 {2,100} | 18 {1.8} | A | — |
| GSF-061204 | 6 | +0.09 +0.04 | 12 | +0.05 0 | 4 | 0 -0.1 | 13.6 | 0.8 | 0 -0.1 | 4.6 | 35.00 {2,100} | 24 {2.4} | A | — |
| GSF-061305 | 6 | +0.09 +0.04 | 13 | +0.05 0 | 5 | 0 -0.1 | 15.0 | 1.1 | 0 -0.1 | — | 35.00 {2,100} | 29 {3.0} | A | 686 |
| GSF-061505 | 6 | +0.09 +0.04 | 15 | +0.05 0 | 5 | 0 -0.1 | 17.0 | 1.2 | 0 -0.1 | — | 35.00 {2,100} | 29 {3.0} | B | 696 |
| GSF-081235 | 8 | +0.09 +0.04 | 12 | +0.05 0 | 3.5 | 0 -0.1 | 13.6 | 0.8 | 0 -0.1 | 5.0 | 26.67 {1,600} | 27 {2.8} | A | 678 |
| GSF-081404 | 8 | +0.09 +0.04 | 14 | +0.05 0 | 4 | 0 -0.1 | 15.6 | 0.8 | 0 -0.1 | 5.6 | 26.67 {1,600} | 31 {3.2} | A | — |
| GSF-081605 | 8 | +0.09 +0.04 | 16 | +0.05 0 | 5 | 0 -0.1 | 18.0 | 1.0 | 0 -0.1 | — | 26.67 {1,600} | 39 {4.0} | B | 688 |
| GSF-082207 | 8 | +0.09 +0.04 | 22 | +0.05 0 | 7 | 0 -0.1 | 25.0 | 1.5 | 0 -0.1 | — | 26.67 {1,600} | 55 {5.6} | B | 608 |

※内径公差についての高精度品を受注生産でお受けします。