

70W オイレスドライメットSTワッシャー



選定の目安

製品紹介

樹脂系ベアリング

複層系ベアリング

金属系ベアリング

エアベアリング

スライドシフター

技術資料

会社案内




適用する内径、厚みから Parts No. を選んでください。

(例)内径28mm、厚み1.5mmの場合

70W - 2815

Parts No. でご指示ください。

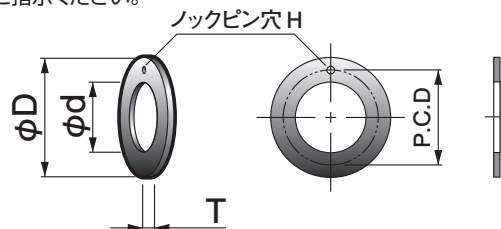

●摺動面は樹脂層です。

Parts No.	内径		外径		厚み		ノックピン穴		ノックピン位置	
	φd	公差	φD	公差	T	公差	H	公差	P.C.D	公差
70W-0815	8	+0.4 +0.1	16	0 -0.3	1.5	-0.015 -0.115	1.5	+0.25 0	12	+0.1 -0.1
70W-1000	10	+0.4 +0.1	18	0 -0.3	1.5	-0.015 -0.115	1.5	+0.25 0	14	+0.1 -0.1
70W-1015	10	+0.4 +0.1	20	0 -0.3	1.5	-0.015 -0.115	1.5	+0.25 0	15	+0.1 -0.1
70W-1215	12	+0.4 +0.1	24	0 -0.3	1.5	-0.015 -0.115	1.5	+0.25 0	18	+0.1 -0.1
70W-1415	14	+0.4 +0.1	26	0 -0.3	1.5	-0.015 -0.115	2.0	+0.25 0	20	+0.1 -0.1
70W-1615	16	+0.4 +0.1	30	0 -0.3	1.5	-0.015 -0.115	2.0	+0.25 0	23	+0.1 -0.1
70W-1715	17	+0.4 +0.1	30	0 -0.3	1.5	-0.015 -0.115	2.0	+0.25 0	23.5	+0.1 -0.1
70W-1815	18	+0.4 +0.1	32	0 -0.3	1.5	-0.015 -0.115	2.0	+0.25 0	25	+0.1 -0.1
70W-2015	20	+0.4 +0.1	36	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	28	+0.1 -0.1
70W-2215	22	+0.4 +0.1	38	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	30	+0.1 -0.1
70W-2315	23	+0.4 +0.1	40	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	31.5	+0.1 -0.1
70W-2415	24	+0.4 +0.1	42	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	33	+0.1 -0.1
70W-2615	26	+0.4 +0.1	44	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	35	+0.1 -0.1
70W-2815	28	+0.4 +0.1	48	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	38	+0.1 -0.1
70W-3215	32	+0.4 +0.1	54	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	43	+0.1 -0.1
70W-3415	34	+0.4 +0.1	58	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	46	+0.1 -0.1
70W-3615	36	+0.4 +0.1	60	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	48	+0.1 -0.1
70W-3815	38	+0.4 +0.1	62	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	50	+0.1 -0.1
70W-3915	39	+0.4 +0.1	66	0 -0.3	1.5	-0.015 -0.115	3.0	+0.25 0	52.5	+0.1 -0.1
70W-4215	42	+0.4 +0.1	66	0 -0.3	1.5	-0.015 -0.115	4.0	+0.25 0	54	+0.1 -0.1
70W-4420	44	+0.4 +0.1	74	0 -0.3	2.0	-0.015 -0.115	4.0	+0.25 0	59	+0.1 -0.1
70W-4720	47	+0.4 +0.1	78	0 -0.3	2.0	-0.015 -0.115	4.0	+0.25 0	62.5	+0.1 -0.1
70W-4820	48	+0.4 +0.1	74	0 -0.3	2.0	-0.015 -0.115	4.0	+0.25 0	61	+0.1 -0.1
70W-5020	50	+0.4 +0.1	84	0 -0.3	2.0	-0.015 -0.115	4.0	+0.25 0	67	+0.1 -0.1
70W-5220	52	+0.4 +0.1	78	0 -0.3	2.0	-0.015 -0.115	5.0	+0.25 0	65	+0.1 -0.1
70W-5525	55	+0.4 +0.1	92	0 -0.3	2.5	-0.015 -0.115	5.0	+0.25 0	73.5	+0.1 -0.1
70W-6025	60	+0.4 +0.1	100	0 -0.3	2.5	-0.015 -0.115	5.0	+0.25 0	80	+0.1 -0.1
70W-6525	65	+0.4 +0.1	108	0 -0.3	2.5	-0.015 -0.115	5.0	+0.25 0	86.5	+0.1 -0.1