

P Series

It is thin long life, it can make 360° in many faculty of software touch and hand, leg and knee etc.



| | | | |
|-------|-----------|---------|-----------|
| Color | B:(Black) | R:(Red) | W:(White) |
|-------|-----------|---------|-----------|

Features


- Operation acts 360° at every position.
- Perfect to operation of hand, elbow, leg, knee.
- ABS resin of resistance impact, resistance insulation is used.
- It is economical in low price.
- 3 colors standard.

Major Applications

Medical appliances, Measuring device, Industrial electron device, Industry sewing machine, Sound device, Education device, Communications device, Photo device, Public welfare device, Each automation device, Others


Thin multi-functional type

- OFL-□-P□Color Type

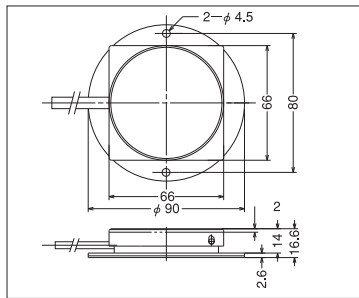



With protection cover (Option)

- OFL-□-PC Type

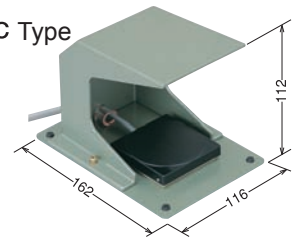

Low Price Type


- OFL-□-P2□Color Type

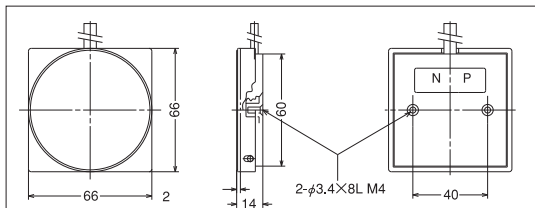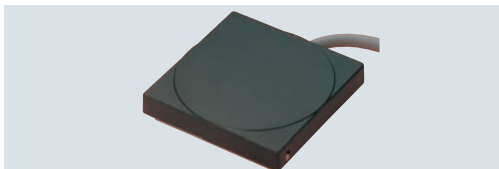

◆ Attachment hole is 2 places (back hole diameter φ 3.4 × depth 8 bag style). Please go M4 tapping screw B1 on use in length 6~8mm of availability screw in tightening torque 78.4N.



Cord is put out from under

- OFL-□-P3□Color Type

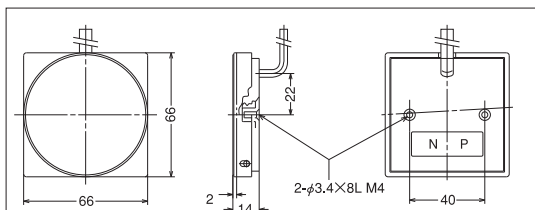

With magnet base

- OFL-□-PM□Color Type

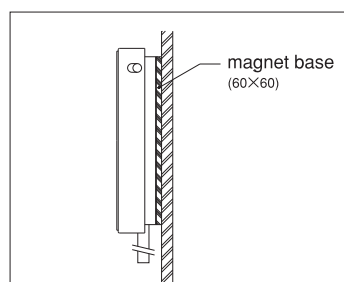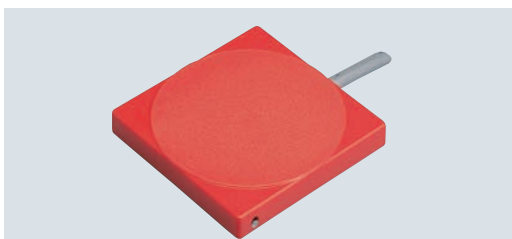

Features

- Attachment the place of operation that it is free! Flat steel plate, easy set. (Attachment construction work is not needed.)



◆ Please pay attention to periphery device because of strong magnetic force.