


## 仕様・規格 |

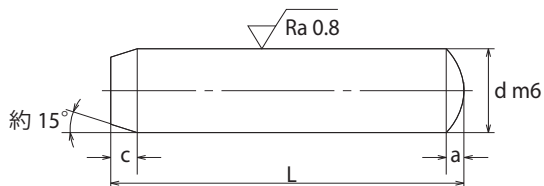

呼び寸法 d x L

d	1	1.2	1.5	1.6	2	2.5	3	4	5	6	8	10	12	13	16	20	25	30
a(約)	0.12	0.16	0.2	0.2	0.25	0.3	0.4	0.5	0.63	0.8	1.0	1.2	1.6	1.6	2.0	2.5	3.0	4.0
c(約)	0.2	0.25	0.3	0.3	0.35	0.4	0.5	0.63	0.8	1.2	1.6	2.0	2.5	2.5	3.0	3.5	4.0	5.0

## L寸法許容差

L寸法	許容差
4 ~ 10	± 0.25
12 ~ 50	± 0.50
55 ~ 200	± 0.75