


# CR

チャッキングリーマ ストレートシャンク  
 Chucking Reamers with Straight Shank

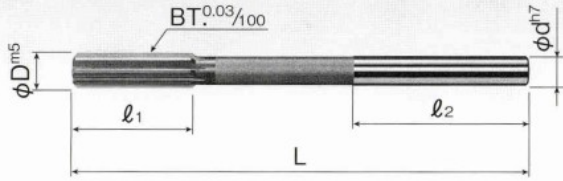

※食付き角45° 45° Chamfer

- 刃長が短いタイプ  
Short flute length type
- ストレートシャンク  
Straight shank
- MCO材(コバルト高速度鋼)を使用  
Uses MCO material (Cobalt high-speed steel)

品番 Product No.	寸法 Size						標準価格 Standard price ¥
	刃径 D	シャン径 d	刃長 ℓ <sub>1</sub>	シャン長 ℓ <sub>2</sub>	全長 L	刃数 NT	
CR030	3.0	3.0	30	50	110	6	7,400
CR031	3.1	3.0	30	50	110	6	7,800
CR032	3.2	3.0	30	50	110	6	7,800
CR033	3.3	3.0	30	50	110	6	7,800
CR034	3.4	3.0	30	50	110	6	7,800
CR035	3.5	3.0	30	50	110	6	7,400
CR036	3.6	3.5	30	50	110	6	7,800
CR037	3.7	3.5	30	50	110	6	7,800
CR038	3.8	3.5	30	50	110	6	7,800
CR039	3.9	3.5	30	50	110	6	7,800
CR040	4.0	3.5	30	50	110	6	7,000
CR041	4.1	3.5	30	50	120	6	7,600
CR042	4.2	3.5	30	50	120	6	7,600
CR043	4.3	3.5	30	50	120	6	7,600
CR044	4.4	3.5	30	50	120	6	7,600
CR045	4.5	3.5	30	50	120	6	7,000
CR046	4.6	4.0	30	50	120	6	7,600
CR047	4.7	4.0	30	50	120	6	7,600
CR048	4.8	4.0	30	50	120	6	7,600
CR049	4.9	4.0	30	50	120	6	7,600
CR050	5.0	4.0	30	50	120	6	6,000
CR051	5.1	4.5	30	50	120	6	6,900
CR052	5.2	4.5	30	50	120	6	6,900
CR053	5.3	4.5	30	50	120	6	6,900
CR054	5.4	4.5	30	50	120	6	6,900
CR055	5.5	4.5	30	50	120	6	6,200
CR056	5.6	5.0	30	50	120	6	6,900
CR057	5.7	5.0	30	50	120	6	6,900
CR058	5.8	5.0	30	50	120	6	6,900
CR059	5.9	5.0	30	50	120	6	6,900
CR060	6.0	5.0	30	50	130	6	6,200
CR061	6.1	5.0	35	50	130	6	7,500
CR062	6.2	5.0	35	50	130	6	7,500
CR063	6.3	5.0	35	50	130	6	7,500
CR064	6.4	5.0	35	50	130	6	7,500

品番 Product No.	寸法 Size						標準価格 Standard price ¥
	刃径 D	シャン径 d	刃長 ℓ <sub>1</sub>	シャン長 ℓ <sub>2</sub>	全長 L	刃数 NT	
CR065	6.5	5.0	35	50	130	6	6,600
CR066	6.6	6.0	35	60	130	6	7,500
CR067	6.7	6.0	35	60	130	6	7,500
CR068	6.8	6.0	35	60	130	6	7,500
CR069	6.9	6.0	35	60	130	6	7,500
CR070	7.0	6.0	35	60	140	6	6,600
CR071	7.1	6.0	35	60	140	6	7,500
CR072	7.2	6.0	35	60	140	6	7,500
CR073	7.3	6.0	35	60	140	6	7,500
CR074	7.4	6.0	35	60	140	6	7,500
CR075	7.5	6.0	35	60	140	6	6,600
CR076	7.6	6.0	40	60	150	6	7,500
CR077	7.7	6.0	40	60	150	6	7,500
CR078	7.8	6.0	40	60	150	6	7,500
CR079	7.9	6.0	40	60	150	6	7,500
CR080	8.0	6.0	40	60	150	6	6,600
CR081	8.1	7.0	40	60	150	6	7,700
CR082	8.2	7.0	40	60	150	6	7,700
CR083	8.3	7.0	40	60	150	6	7,700
CR084	8.4	7.0	40	60	150	6	7,700
CR085	8.5	7.0	40	60	150	6	7,000
CR086	8.6	7.0	40	60	160	6	7,700
CR087	8.7	7.0	40	60	160	6	7,700
CR088	8.8	7.0	40	60	160	6	7,700
CR089	8.9	7.0	40	60	160	6	7,700
CR090	9.0	7.0	40	60	160	6	7,000
CR091	9.1	8.0	40	60	160	6	8,000
CR092	9.2	8.0	40	60	160	6	8,000
CR093	9.3	8.0	40	60	160	6	8,000
CR094	9.4	8.0	40	60	160	6	8,000
CR095	9.5	8.0	40	60	160	6	7,400
CR096	9.6	8.0	40	60	160	6	8,000
CR097	9.7	8.0	40	60	160	6	8,000
CR098	9.8	8.0	40	60	160	6	8,000
CR099	9.9	8.0	40	60	160	6	8,000

リーマ
エンドミル
ドリル
面取り/座ぐり
メタルソー
カッター
ハンド
マシン
チャッキング
スピードリーマ
ブリッジ
テーパピン
シェル