




Tolerance for cutter Diameter
Dia 1mm-2.9 mm 0.000/-0.010

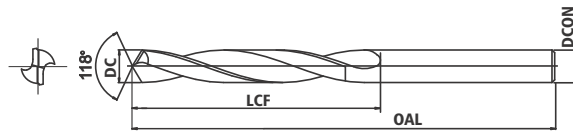

2021	Drill Diameter	OAL	Flute Length	Shank Diameter
EDP No.	DC	OAL	LCF	DCON
202101000	1	30	11	1
202101100	1.1	30	11	1.1
202101200	1.2	30	13	1.2
202101300	1.3	30	13	1.3
202101400	1.4	30	13	1.4
202101500	1.5	30	13	1.5
202101600	1.6	40	17.5	1.6
202101700	1.7	40	17.5	1.7
202101800	1.8	40	17.5	1.8
202101900	1.9	40	17.5	1.9
202102000	2	40	17.5	2
202102100	2.1	40	17.5	2.1
202102200	2.2	40	17.5	2.2
202102300	2.3	40	17.5	2.3
202102400	2.4	40	17.5	2.4
202102500	2.5	40	17.5	2.5
202102600	2.6	45	20	2.6
202102700	2.7	45	20	2.7
202102800	2.8	45	20	2.8
202102900	2.9	45	20	2.9