

A PSF STEELOX ★★☆☆

POLIFAN flap disc with high stock removal rate and long tool life.

Advantages:

- Fast work progress and high economic efficiency thanks to the high stock removal rate.
- Long tool life.
- Also ideal for cordless angle grinders.

Materials that can be worked:

steel, stainless steel (INOX)


Applications:

surface grinding, weld dressing

Abrasive:

Aluminium oxide A

PFERDVALUE:

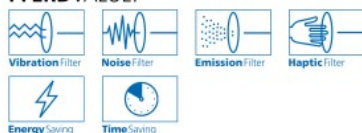

D [mm]	Grit size				H [mm]	Max. RPM		Description
	40	60	80	120				
EAN 4007220								

Flat type PFF



115	512388	512395	512401	512418	22.23	13,300	10	PFF 115 A ... PSF STEELOX
125	512425	512432	512449	512456	22.23	12,200	10	PFF 125 A ... PSF STEELOX
180	512463	-	-	-	22.23	8,500	10	PFF 180 A ... PSF STEELOX

Conical type PFC



115	444559	444566	444573	444580	22.23	13,300	10	PFC 115 A ... PSF STEELOX
125	444603	444610	444627	444634	22.23	12,200	10	PFC 125 A ... PSF STEELOX
180	444689	444696	-	-	22.23	8,500	10	PFC 180 A ... PSF STEELOX

Z PSF STEELOX ★★☆☆

POLIFAN flap disc with aggressive stock removal rate and long tool life.

Advantages:

- Fast work progress and high economic efficiency thanks to the aggressive stock removal rate.
- Long tool life.
- Also suitable for low-power angle grinders.

Materials that can be worked:

steel, stainless steel (INOX)


Applications:

surface grinding, weld dressing, chamfering, deburring

Abrasive:

Zirconia alumina Z

PFERDVALUE:

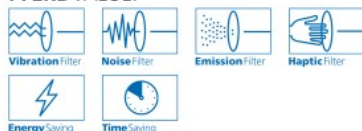

D [mm]	Grit size				H [mm]	Max. RPM		Description
	40	60	80	120				
EAN 4007220								

Flat type PFF



100	750117	750124	750131	-	16.0	15,300	10	PFF 100 Z ... PSF STEELOX/16,0
115	096772	096789	512500	-	22.23	13,300	10	PFF 115 Z ... PSF STEELOX
125	096796	512524	512531	-	22.23	12,200	10	PFF 125 Z ... PSF STEELOX
180	096833	512555	-	-	22.23	8,500	10	PFF 180 Z ... PSF STEELOX

Conical type PFC



100	953273	953280	953297	953303	16.0	15,300	10	PFC 100 Z ... PSF STEELOX/16,0
115	096307	096383	096390	934203	22.23	13,300	10	PFC 115 Z ... PSF STEELOX
125	096437	096499	096635	934210	22.23	12,200	10	PFC 125 Z ... PSF STEELOX
150	805923	805930	-	-	22.23	10,200	10	PFC 150 Z ... PSF STEELOX
180	096710	096765	934227	934234	22.23	8,500	10	PFC 180 Z ... PSF STEELOX