



Signal Horn



90dB at 1m (BM-H Type)

2 Channels

IP34 (BM-D Front Only)

Ø30

**NPN/PNP
Open-collector**




Compact Signal Horn designed to integrate with control panel, switchboard and other production equipment applications.

FEATURES

- Built-in Alarm with an audible sound of up to 90dB (at 1m*1).
- Has two selectable alarm sound patterns.
- Three Types to choose from; Standard (BM), High Volume (BM-H), Drip-proof (BM-D)
- Body is compact and lightweight (100g).
- The 24V type is compatible with NPN and PNP inputs.
- Has the CE mark and conforms to the requirements for the EC directive. (For AC/DC 24V only.)

*1 Model BM-H: 90dB (at 1m); Model BM: 85dB (at 1m); Model BM-D: 80dB (at 1m)

How to Order

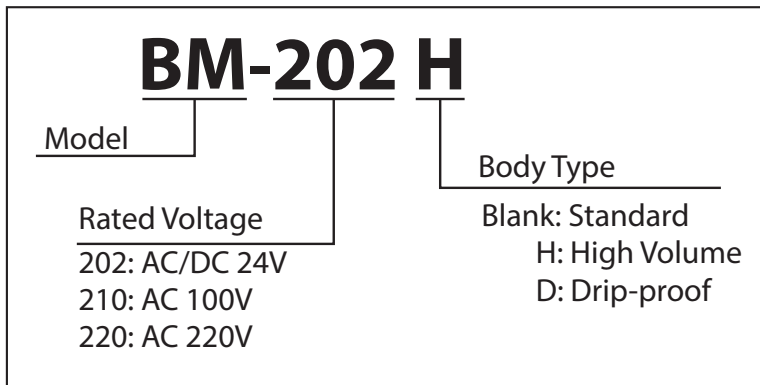

Application Example

