

# BK



## Audible Alarm



- 95dB at 1m
- 8 Channels / 32 Sounds
- IP54
- 120
- NPN  
Open-collector

## The BK Series can play melodies, chimes and alarms with variable audible control and a compact but loud speaker.


### FEATURES

- 32 pre-recorded sounds in one unit to be used for various applications.
- Maximum output level of 90dB (at 1m) is suitable for use in a noisy factory.
- Rotary switch to easily change sound groups and adjust volume output from the front panel, even after installation.
- Use bit input to select a sound group to playback 8 pre-recorded sounds.
- A new sound group can be created from the 32 sounds by using an optional memory card (sold separately).
- Compliant with the RoHS directive
- Has the CE mark and conforms to the requirements (for 12V/24V type) for the EC directive.
- Is a UL recognized component (File No. E24210).

### AVAILABLE BY SPECIAL ORDER

- PNP open collector transistor type.

### Dimensions

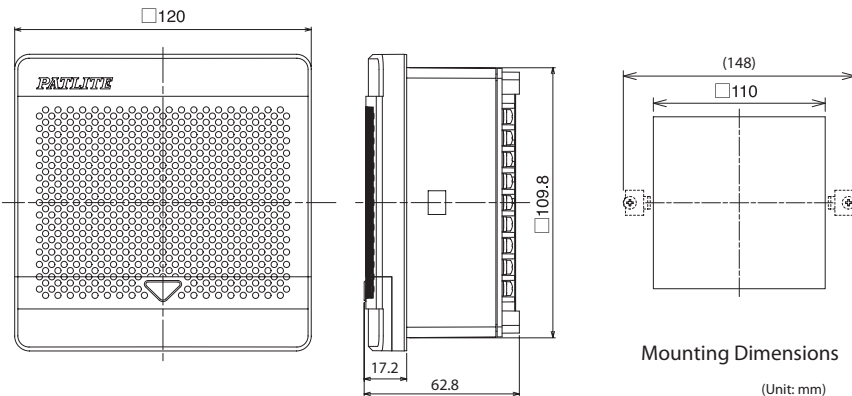

### How to Order

**BK-24A-J**

Model	Color
Rated Voltage	J: Light Gray K: Dark Gray
24 : DC 12-24V 100: AC 100V 220: AC 220V	Sound Type
	A: Type A* C: Type C* D: Type D* E: Type E

\*Copyright laws limits availability to Japan only.

