


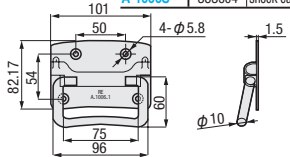

 

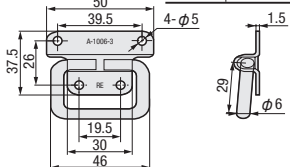

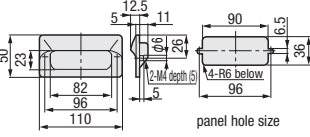

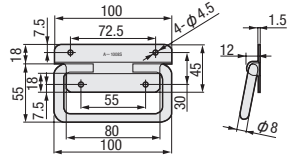

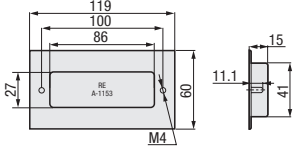

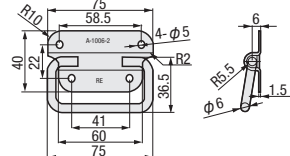

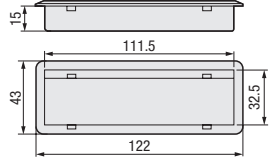

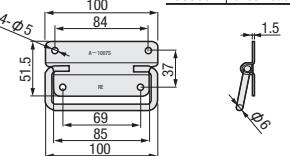

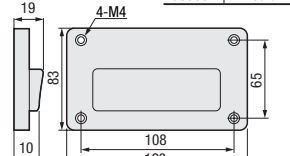

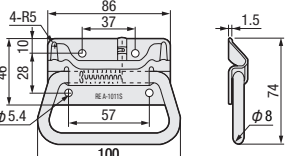

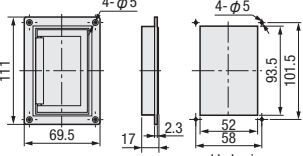

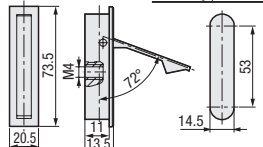

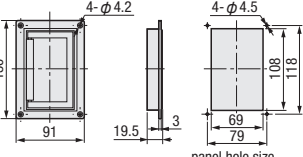


取手 / スプリング付取手 / 埋め込み取手

Handle / Spring Handle / Embedded Handle

RE
REG
(Brand code: REG)

Brand code: When placing an order, please indicate the Brand code to get a quicker response.

<p>Handle</p> 	<p>A-1006-1M A-1006S</p> <table border="1"> <tr> <th>Part Number</th> <th>M</th> <th>S</th> </tr> <tr> <td>A-1006-1M</td> <td>cold-rolled iron</td> <td>color zinc</td> </tr> <tr> <td>A-1006S</td> <td>SUS304</td> <td>shock casting</td> </tr> </table> 	Part Number	M	S	A-1006-1M	cold-rolled iron	color zinc	A-1006S	SUS304	shock casting	<p>Embedded Handle</p> 	<p>AP-197-1-□P</p> <table border="1"> <tr> <th>Part Number</th> <th>A(mm)</th> </tr> <tr> <td>AP-197-1-2P</td> <td>plate thickness 1.2</td> </tr> <tr> <td>AP-197-1-3P</td> <td>plate thickness 1.6</td> </tr> </table> <p>Engineering plastics</p> 	Part Number	A(mm)	AP-197-1-2P	plate thickness 1.2	AP-197-1-3P	plate thickness 1.6
Part Number	M	S																
A-1006-1M	cold-rolled iron	color zinc																
A-1006S	SUS304	shock casting																
Part Number	A(mm)																	
AP-197-1-2P	plate thickness 1.2																	
AP-197-1-3P	plate thickness 1.6																	
<p>Handle</p> 	<p>A-1006-3S</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>SUS304</td> <td>shock casting</td> </tr> </table> 	M	S	SUS304	shock casting	<p>Embedded Handle</p> 	<p>AP-183-2P</p> <table border="1"> <tr> <th>M</th> </tr> <tr> <td>Engineering plastics</td> </tr> </table>  <p>panel hole size</p>	M	Engineering plastics									
M	S																	
SUS304	shock casting																	
M																		
Engineering plastics																		
<p>Handle</p> 	<p>A-1008S</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>SUS304</td> <td>shock casting</td> </tr> </table> 	M	S	SUS304	shock casting	<p>Embedded Handle</p> 	<p>A-1153S</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>SUS304</td> <td>wiredrawing</td> </tr> </table> 	M	S	SUS304	wiredrawing							
M	S																	
SUS304	shock casting																	
M	S																	
SUS304	wiredrawing																	
<p>Handle</p> 	<p>A-1006-2S</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>SUS304</td> <td>shock casting</td> </tr> </table> 	M	S	SUS304	shock casting	<p>Embedded Handle</p> 	<p>A-1159P</p> <table border="1"> <tr> <th>M</th> </tr> <tr> <td>Engineering plastics</td> </tr> </table> 	M	Engineering plastics									
M	S																	
SUS304	shock casting																	
M																		
Engineering plastics																		
<p>Handle</p> 	<p>A-1007S</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>SUS304</td> <td>shock casting</td> </tr> </table> 	M	S	SUS304	shock casting	<p>Embedded Handle</p> 	<p>A-1181S</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>SUS304</td> <td>wiredrawing</td> </tr> </table> 	M	S	SUS304	wiredrawing							
M	S																	
SUS304	shock casting																	
M	S																	
SUS304	wiredrawing																	
<p>Spring Handle</p> 	<p>A-1011S</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>SUS304</td> <td>shock casting</td> </tr> </table> 	M	S	SUS304	shock casting	<p>Foldable Embedded Handle</p> 	<p>A-5002-1Z</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>zinc alloy</td> <td>sandblasting chrome plating</td> </tr> </table>  <p>panel hole size</p>	M	S	zinc alloy	sandblasting chrome plating							
M	S																	
SUS304	shock casting																	
M	S																	
zinc alloy	sandblasting chrome plating																	
<p>Rotating Handle</p> 	<p>A-5001-1Z</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>zinc alloy</td> <td>chrome flash</td> </tr> </table>  <p>panel hole size</p>	M	S	zinc alloy	chrome flash	<p>Foldable Embedded Handle</p> 	<p>A-5003-1Z</p> <table border="1"> <tr> <th>M</th> <th>S</th> </tr> <tr> <td>zinc alloy</td> <td>spraying (black)</td> </tr> </table>  <p>panel hole size</p>	M	S	zinc alloy	spraying (black)							
M	S																	
zinc alloy	chrome flash																	
M	S																	
zinc alloy	spraying (black)																	