

# ダブルトーションばね


## ばね用ステンレス鋼線

材質 SUS304-WPB

納期 **即日発送** (PM5:00までご注文分) ※1

RoHS  
適合品

ネット  
対応品

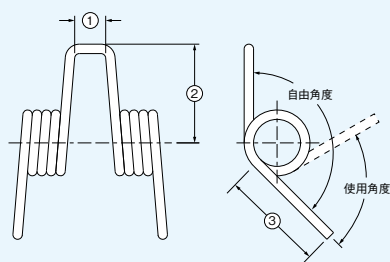

線径 mm	内径 mm	長さ			製品番号	巻数 右	巻数 左	自由角度	ばね定数		使用角度	単価 円		
		①	②	③					N・mm/deg	(kgf・mm/deg)		1~9	10~49	50~個
0.6	5.0	5	10	16	F7565	2	2	90°	1.04	0.106	43	190	170	150
					F7566	3	3		0.72	0.073	62			
					F7551	3	3	135°	0.75	0.076	60			
					F7552	4	4		0.57	0.058	79			
0.8	5.5	5	11	17	F7567	2	2	90°	2.93	0.299	36	210	190	170
					F7568	3	3		2.03	0.207	52			
					F7553	3	3	135°	2.11	0.215	49			
					F7554	4	4		1.59	0.162	66			
1.0	6.0	5	12	18	F7569	2	2	90°	6.44	0.657	31	240	215	190
					F7570	3	3		4.46	0.455	45			
					F7555	3	3	135°	4.63	0.472	43			
					F7556	4	4		3.51	0.358	58			
1.2	8.0	7	16	24	F7571	3	3	90°	7.03	0.717	49	305	275	245
					F7572	4	4		5.38	0.549	64			
					F7557	4	4	135°	5.54	0.565	62			
					F7558	5	5		4.46	0.455	78			
1.6	10.0	8	20	30	F7573	3	3	90°	17.6	1.795	45	430	390	345
					F7574	4	4		13.5	1.377	58			
					F7559	4	4	135°	13.9	1.417	57			
					F7560	5	5		11.8	1.203	71			
2.0	12.0	10	24	35	F7575	3	3	90°	35.6	3.630	41	480	430	385
					F7576	4	4		27.2	2.774	48			
					F7561	4	4	135°	28.1	2.865	53			
					F7562	5	5		22.6	2.305	66			
2.3	14.0	16	28	40	F7577	3	3	90°	53.6	5.466	41	525	475	425
					F7578	4	4		41.0	4.181	53			
					F7563	4	4	135°	42.2	4.303	52			
					F7564	5	5		34.0	3.467	64			

※1 在庫割れの場合、納期は別途ご相談  
表示価格は全て本体価格です。