


CoroTurn® 107 boring bar for turning

Screw clamp design

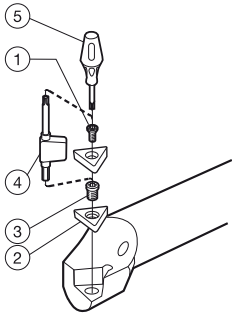

Metric version

	Spare parts			Included parts	Accessories
	1	2	3	4	5
Ordering code	Insert screw	Shim	Shim screw	Key	Screwdriver
A08H-SCLCR/L 06	5513 020-46			5680 051-02	5680 046-03
A08H-SCLCR/L 06-R	5513 020-46			5680 051-02	5680 046-03
A10K-SCLCR/L 06	5513 020-46			5680 051-02	5680 046-03
A10K-SCLCR/L 06-R	5513 020-46			5680 051-02	5680 046-03
A12M-SCLCR/L 06	5513 020-46			5680 051-02	5680 046-03
A12M-SCLCR/L 06-R	5513 020-46			5680 051-02	5680 046-03
A16R-SCLCR/L 06	5513 020-03			5680 051-02	5680 046-03
A16R-SCLCR/L 06-R	5513 020-03			5680 051-02	5680 046-03
A16R-SCLCR/L 09	5513 020-09			5680 049-01	5680 046-02
A16R-SCLCR/L 09-R	5513 020-09			5680 049-01	5680 046-02
A20S-SCLCR/L 09	5513 020-09			5680 049-01	5680 046-02
A20S-SCLCR/L 09-R	5513 020-09			5680 049-01	5680 046-02
A25T-SCLCR/L 09	5513 020-10			5680 049-01	5680 046-02
A25T-SCLCR/L 12	5513 020-17			5680 049-02	5680 046-02
A32T-SCLCR/L 12	5513 020-18	5322 232-02	5512 090-03	5680 049-02	5680 046-02
A40T-SCLCR/L 12	5513 020-18	5322 232-02	5512 090-03	5680 049-02	5680 046-02
A10K-SDQCR/L 07	5513 020-03			5680 051-02	5680 046-03
A10K-SDQCR/L 07-R	5513 020-03			5680 051-02	5680 046-03
A10K-SDUCR/L 07	5513 020-48			5680 051-02	5680 046-03
A10K-SDUCR/L 07-ER	5513 020-03			5680 051-02	5680 046-03
A12M-SDQCR/L 07	5513 020-03			5680 051-02	5680 046-03
A12M-SDQCR/L 07-R	5513 020-03			5680 051-02	5680 046-03
A12M-SDUCR/L 07	5513 020-03			5680 051-02	5680 046-03
A12M-SDUCR/L 07-ER	5513 020-03			5680 051-02	5680 046-03
A12M-SDXCR/L 07	5513 020-03			5680 051-02	5680 046-03
A12M-SDXCR/L 07-R	5513 020-03			5680 051-02	5680 046-03
A16K-SDXCR/L 07-R	5513 020-03			5680 051-02	5680 046-03
A16R-SDQCR/L 07	5513 020-03			5680 051-02	5680 046-03
A16R-SDQCR/L 07-R	5513 020-03			5680 051-02	5680 046-03
A16R-SDUCR/L 07	5513 020-03			5680 051-02	5680 046-03
A16R-SDUCR/L 07-ERX	5513 020-03			5680 051-02	5680 046-03
A16R-SDUCR/L 07-EX	5513 020-03			5680 051-02	5680 046-03
A16R-SDUCR/L 07-R	5513 020-03			5680 051-02	5680 046-03
A16R-SDXCR/L 07	5513 020-03			5680 051-02	5680 046-03
A16R-SDXCR/L 07-R	5513 020-03			5680 051-02	5680 046-03
A20M-SDXCR/L 11-R	5513 020-09			5680 049-01	5680 046-02
A20S-SDQCR/L 11	5513 020-09			5680 049-01	5680 046-02
A20S-SDQCR/L 11-R	5513 020-09			5680 049-01	5680 046-02
A20S-SDUCR/L 07-ERX	5513 020-03			5680 051-02	5680 046-03
A20S-SDUCR/L 07-EX	5513 020-03			5680 051-02	5680 046-03
A20S-SDUCR/L 11	5513 020-09			5680 049-01	5680 046-02
A20S-SDUCR/L 11-R	5513 020-09			5680 049-01	5680 046-02
A20S-SDXCR/L 11	5513 020-09			5680 049-01	5680 046-02
A20S-SDXCR/L 11-R	5513 020-09			5680 049-01	5680 046-02
A25T-SDQCR/L 11	5513 020-10			5680 049-01	5680 046-02
A25T-SDUCR/L 07-DX	5513 020-03			5680 051-02	5680 046-03

Keys (mm/Torx Plus) sizes, see page P4

For optional shims, see page A133.

Accessories, must be ordered separately.