


T-Max® P insert for turning

Rhombic 55°

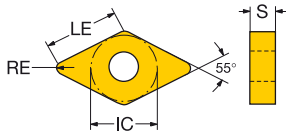

		ISO CODE	P								M					K				S				ANSI CODE									
			1515	1525	4205	4235	4315	4325	5015	GC30	1115	1125	2015	2025	2035	235	GC15	3005	3205	3210	3215	GC30	H13A		1105	1115	1125	GC15	H13A	S05F			
	11	3/8	DNMX 11 04 04-WF	☆	☆																									DNMX 331-WF			
			DNMX 11 04 08-WF	☆	☆	☆												☆							☆					DNMX 332-WF			
	15	1/2	DNMX 15 04 04-WF	☆	☆																										DNMX 431-WF		
			DNMX 15 04 08-WF	☆	☆	☆							☆	☆										☆								DNMX 432-WF	
			DNMX 15 04 12-WF																													DNMX 433-WF	
			DNMX 15 06 04-WF																													DNMX 441-WF	
		DNMX 15 06 08-WF	☆	☆	☆							☆	☆				☆					☆								DNMX 442-WF			
		DNMX 15 06 12-WF																												DNMX 443-WF			
	11	3/8	DNMG 11 04 04-PF	☆	☆																									DNMG 331-PF			
			DNMG 11 04 08-PF	☆	☆	☆																								DNMG 332-PF			
			DNMG 11 04 12-PF	☆	☆	☆																									DNMG 333-PF		
	15	1/2	DNMG 15 04 04-PF	☆	☆																										DNMG 431-PF		
			DNMG 15 04 08-PF	☆	☆	☆																									DNMG 432-PF		
			DNMG 15 04 12-PF	☆	☆	☆																										DNMG 433-PF	
DNMG 15 06 04-PF			☆	☆																											DNMG 441-PF		
		DNMG 15 06 08-PF	☆	☆	☆																									DNMG 442-PF			
		DNMG 15 06 12-PF	☆	☆	☆																									DNMG 443-PF			
	11	3/8	DNMG 11 04 04-KF															☆												DNMG 331-KF			
			DNMG 11 04 08-KF															☆												DNMG 332-KF			
	15	1/2	DNMG 15 04 04-KF																☆												DNMG 431-KF		
			DNMG 15 04 08-KF																☆												DNMG 432-KF		
			DNMG 15 06 04-KF																	☆												DNMG 441-KF	
			DNMG 15 06 08-KF																	☆												DNMG 442-KF	
		DNMG 15 06 12-KF															☆												DNMG 443-KF				
Finishing		11	3/8	DNMG 11 04 04-MF							☆	☆	☆	☆									☆	☆	☆					DNMG 331-MF			
				DNMG 11 04 08-MF								☆	☆	☆	☆									☆	☆	☆					DNMG 332-MF		
		15	1/2	DNMG 15 04 04-MF								☆	☆	☆	☆									☆	☆	☆				☆	DNMG 431-MF		
				DNMG 15 04 08-MF									☆	☆	☆	☆									☆	☆	☆				☆	DNMG 432-MF	
				DNMG 15 04 12-MF										☆	☆	☆	☆									☆	☆	☆				☆	DNMG 433-MF
				DNMG 15 06 04-MF																							☆	☆	☆			☆	DNMG 441-MF
				DNMG 15 06 08-MF																							☆	☆	☆			☆	DNMG 442-MF
				DNMG 15 06 12-MF																							☆	☆	☆			☆	DNMG 443-MF
		11	3/8	DNMG 11 04 04-MF													☆														DNMG 331-MF		
				DNMG 11 04 08-MF																													DNMG 332-MF
				DNMG 11 04 12-MF																													DNMG 333-MF
		15	1/2	DNMG 15 04 04-MF																												DNMG 431-MF	
DNMG 15 04 08-MF																																DNMG 432-MF	
DNMG 15 04 12-MF																																DNMG 433-MF	
		DNMG 15 06 04-MF																											DNMG 441-MF				
		DNMG 15 06 08-MF																												DNMG 442-MF			
		DNMG 15 06 12-MF																												DNMG 443-MF			
	11	3/8	DNMG 11 04 04-LC	☆																										DNMG 331-LC			
			DNMG 11 04 08-LC	☆																											DNMG 332-LC		
			DNMG 11 04 12-LC	☆	☆																											DNMG 333-LC	
	15	1/2	DNMG 15 04 04-LC	☆	☆																										DNMG 431-LC		
			DNMG 15 04 08-LC	☆	☆																											DNMG 432-LC	
			DNMG 15 06 04-LC	☆																												DNMG 441-LC	
		DNMG 15 06 08-LC	☆																											DNMG 442-LC			

For dimensions, see code key on page I14.

