


T-Max® P head for turning

Lever clamp design

CoroTurn® SL - High precision coolant supply

KAPR 75°
PSIR 15°

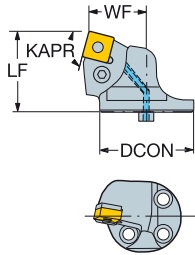

- SNMM
- SNMG
- SNMA, SNGA

							Dimensions, mm, inch								
						Ordering code	DCON	LF	WF	HF				MIID	
		12	1/2	40	35.0	1	40	35.0	22.0	0.0	80	3.9	0.16	SNMG 12 04 08	
					1.378		1.575	1.378	.866	.000	1160		.356	SNMG 432	

N = Neutral, R = Right hand, L = Left hand

A7

I1

G1

I38