



# Cartridge for turning

Lever clamp design

Cartridge for railway wheel re-turning


KAPR  
PSIR

90°  
0°

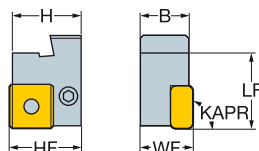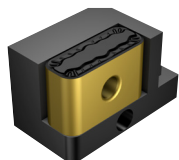

					Dimensions, mm, inch							
	CZ <sub>MS</sub>	OHX	CNSC	Ordering code	B	H	LF	WF	HF	Nm	kg	MIID
19	L3223	35.0	0	R/L175.32-3223-19	22.6	32.0	35.0	23.0	32.0	5.0	0.13	LNMX 19 19 40
	R3223	1.378			.890	1.260	1.378	.906	1.260			LNMX 19 19 40
30	R3223	35.0	0	R/L175.32-3223-30	22.6	32.0	35.0	23.0	32.0	5.0	0.14	LNMX 30 19 40
	R3223	1.378			.890	1.260	1.378	.906	1.260			LNMX 30 19 40

 R = Right hand, L = Left hand




A95



I1



 I38



I34